


# Rittal – The System.

Faster – better – everywhere.

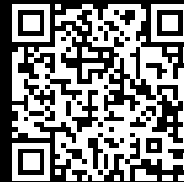

## TE 7888.944 Distributor Racks

State: 8/23/2025 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# TE 7888.944 - Distributor Racks TE 8000 open

For optimum accessibility from all sides during assembly and installation.

## Features

Model No.	TE 7888.944
Benefits	Optimum accessibility from all sides during assembly and installation Unrestricted airflow, due to the open design The distance between mounting levels is infinitely variable
Material	Carbon steel
Surface finish	Powder-coated
General color	RAL 7035
Color	RAL 7035
Supply includes	Self-supporting mounting frame, with 482.6 mm (19") mounting level front and rear Roof-plate, prepared for accommodating a cable organizer Open base frame with 2 system chassis for individual configuration fitted in the width 4 leveling feet, M10 (supplied loose) Roof plate with brush strip on both sides
Dimensions	Width: 800 mm Height: 2,000 mm Depth: 1,000 mm Width: 31.5 " Height: 78.7 " Depth: 39.4 "
Height units	42 U
Height units	42 U
Mounting space to 19" level, front/rear	80 mm / 130 mm
Distance between levels as delivered	745 mm 29.3 "

# Features

Load capacity	7,000 N
Base material	Carbon steel
Packaging unit	1 pc(s).
Net weight	55
Gross weight	59.5
EAN	4028177801332
E-Number Sweden	E7282510
ETIM 9	EC002507
ECLASS 8.0	27180602