


Rittal – The System.

Faster – better – everywhere.

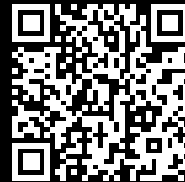

DK 7955.510

PDU UK, basic version

State: 8/23/2025 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7955.510 - PDU UK, basic version

The compact design allows quick mounting in the zero U space of TS IT network and server enclosures. Input with CEE plug (16 A/32 A) with BS 1363 (UK) outputs. Distribution output from 3.7 kW to 22 kW.

Features

Model No.	DK 7955.510
Product description	Robust, compact basic power distributor for the IT environment. Thanks to the compact size of the PDU, all IT racks can easily be equipped with a professional power distribution system. In the case of the TS IT rack, mounting is even possible without tools. The compact design enables easy mounting.
Material	Aluminum section, black anodized
Dimensions	Width: 44 mm Depth: 62 mm Length: 440 mm Width: 1.73 " Depth: 2.44 " Length: 17.3 "
Number of sockets and type	6 x C13 / 1 x C19
Outlets	6 x GB (type G, BS 1363)
Rated current (max.)	13 A
Infeeds	Qty.: 1 Phases per infeed: 1~
Length of connection cable	3 m 118 "
Type of connection (electrical)	UK
Operating temperature range	0 °C...45 °C 32 °F...113 °F
Ambient humidity (non-condensing)	10...95 %

Features

Storage temperature range	-25 °C...70 °C -13 °F...158 °F
Suitable for	Enclosure type: TS IT: ≤ 800 mm Enclosure type: TS IT: ≤ 31.5 "
Packaging unit	1 pc(s).
Net weight	1.24
Gross weight	1.42
Customs tariff number	85366990
EAN	4028177685024
ECLASS 8.0	27142604