


Rittal – The System.

Faster – better – everywhere.

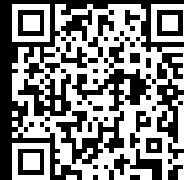

SZ 7967.000

Spacer

State: 9/2/2025 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 7967.000 - Spacer for roof plate

For raising the roof for ventilation purposes, available in three different heights. Not suitable for crane transport.



Features

Model No.	SZ 7967.000
Product description	For raising the roof for ventilation purposes, available in three different heights.
Material	Hexagon steel section
Surface finish	Zinc-plated
Supply includes	Assembly components
Mounting tip	Not suitable for combination with 19" mounting frame Not suitable for crane transportation
Dimensions	Height: 50 mm Height: 1.97 "
Dimensions	Thread: M12
Suitable for	Enclosure type: VX TS
Packaging unit	4 pc(s).
Net weight	0.444
Gross weight	0.539
PCF/VE (cradle-to-gate)	2.1 kg CO2 eq (Cat B)

Features

Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared
Customs tariff number	73269098
EAN	4028177186934
E-Number Sweden	E7239676
ETIM 9	EC002625
ECLASS 8.0	27189234