

# Rittal – The System.

Faster – better – everywhere.



## SZ 7967.000

## Spacer

State: 6/4/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 7967.000 - Spacer for roof plate

For raising the roof for ventilation purposes, available in three different heights. Not suitable for crane transport.

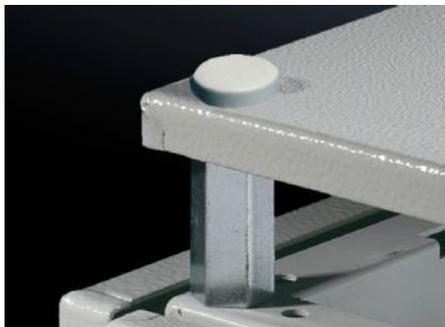

## Features

Model No.	SZ 7967.000
Product description	For raising the roof for ventilation purposes, available in three different heights.
Material	Hexagon steel section
Surface finish	Zinc-plated
Supply includes	Assembly components
Mounting tip	Not suitable for combination with 19" mounting frame Not suitable for crane transportation
Dimensions	Height: 50 mm Height: 1.97 "
Dimensions	Thread: M12
Suitable for	Enclosure type: VX TS
Packaging unit	4 pc(s).
Net weight	0.444 kg
Gross weight	0.539 kg
PCF/VE (cradle-to-gate)	2.1 kg CO2 eq (Cat B)

# Features

---

Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared
Customs tariff number	73269098
ETIM 9	EC002625
ECLASS 8.0	27189234
Product description	DK Spacer, L: 50 mm, For TS roof plate

---