


Rittal – The System.

Faster – better – everywhere.

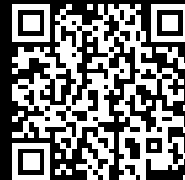

SK 7980.100 Fan expansion kit

State: 7/13/2025 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SK 7980.100 - Fan expansion kit

For retro-fitting various fan units or to expand the fan mounting plate

Features

Model No.	SK 7980.100
Product description	Can be used as a stand-alone fan and for retrofitting various fan units or to extend the fan mounting plate.
Supply includes	Fans Connection cable (0.61 m) Assembly components
Unimpeded air flow (with chopped fiber filter)	At 50 Hz: 108 m³/h At 60 Hz: 120 m³/h At 50 Hz: 63.6 cfm At 60 Hz: 70.6 cfm
Rated operating voltage	230 V, 1~, 50 Hz/60 Hz
Rated power Pel	At 50 Hz: 14 W At 60 Hz: 12 W
Dimensions	Width: 119 mm Height: 119 mm Depth: 25 mm Width: 4.69 " Height: 4.69 " Depth: 0.98 "
Operating temperature range	-20 °C...70 °C -4 °F...158 °F
Noise pressure level	At 50 Hz: 34 dB(A) At 60 Hz: 34 dB(A)
Packaging unit	1 pc(s).
Net weight	0.43
Gross weight	0.486
Customs tariff number	84149000

Features

EAN	4028177187313
ETIM 9	EC000320
ECLASS 8.0	27180716