


Rittal – The System.

Faster – better – everywhere.

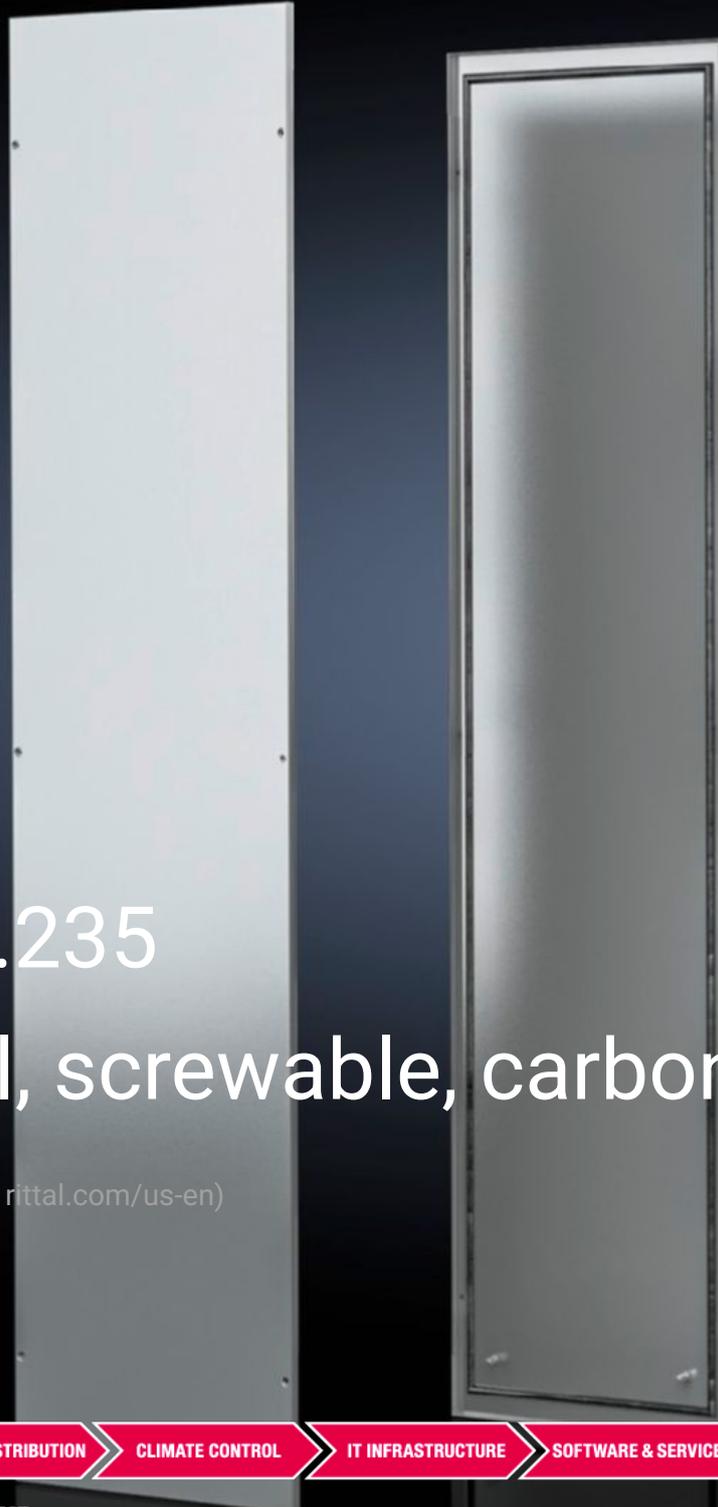

TS 8105.235

Side wall, screwable, carbon steel

State: 5/7/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES



FRIEDHELM LOH GROUP

TS 8105.235 - Side wall, screwable, carbon steel for TS, TS IT

Side panels, screw-fastened, sheet steel, for TS.

Features

| | |
|-------------------------------------|---|
| Model No. | TS 8105.235 |
| Benefits | Automatic potential equalization and higher EMC protection thanks to enclosure panel holders with grounding insert Easy positioning with the location aid Grounding bolt with contact surface |
| Material | Carbon steel, 1.5 mm |
| Surface finish | Dipcoat-primed, powder-coated on the outside |
| Color | RAL 7035 |
| Supply includes | Assembly components |
| Note | Enclosure panel holders may optionally be fitted from the inside or outside of the enclosure. Area available for population: External dimension – 100 mm |
| Suitable for | Enclosure type: TS TS IT Height: 2,000 mm Depth: 500 mm Enclosure type: TS TS IT Height: 78.7 “ Depth: 19.7 “ |
| Protection category IP to IEC 60529 | IP 55 |
| Base material | Carbon steel |
| Packaging unit | 2 pc(s). |
| Net weight | 22.8 kg |
| Gross weight | 24.2 kg |

Features

| | |
|-----------------------|---|
| Customs tariff number | 94039910 |
| ETIM 9 | EC002524 |
| ECLASS 8.0 | 27182101 |
| Product description | TS Side panel, screw-fastened, for TS, TS IT, for WD: 2000x500 mm, Sheet steel |

Approvals

| | |
|--------------|------------------------------|
| Explanations | Declaration of conformity UK |
|--------------|------------------------------|