


Rittal – The System.

Faster – better – everywhere.

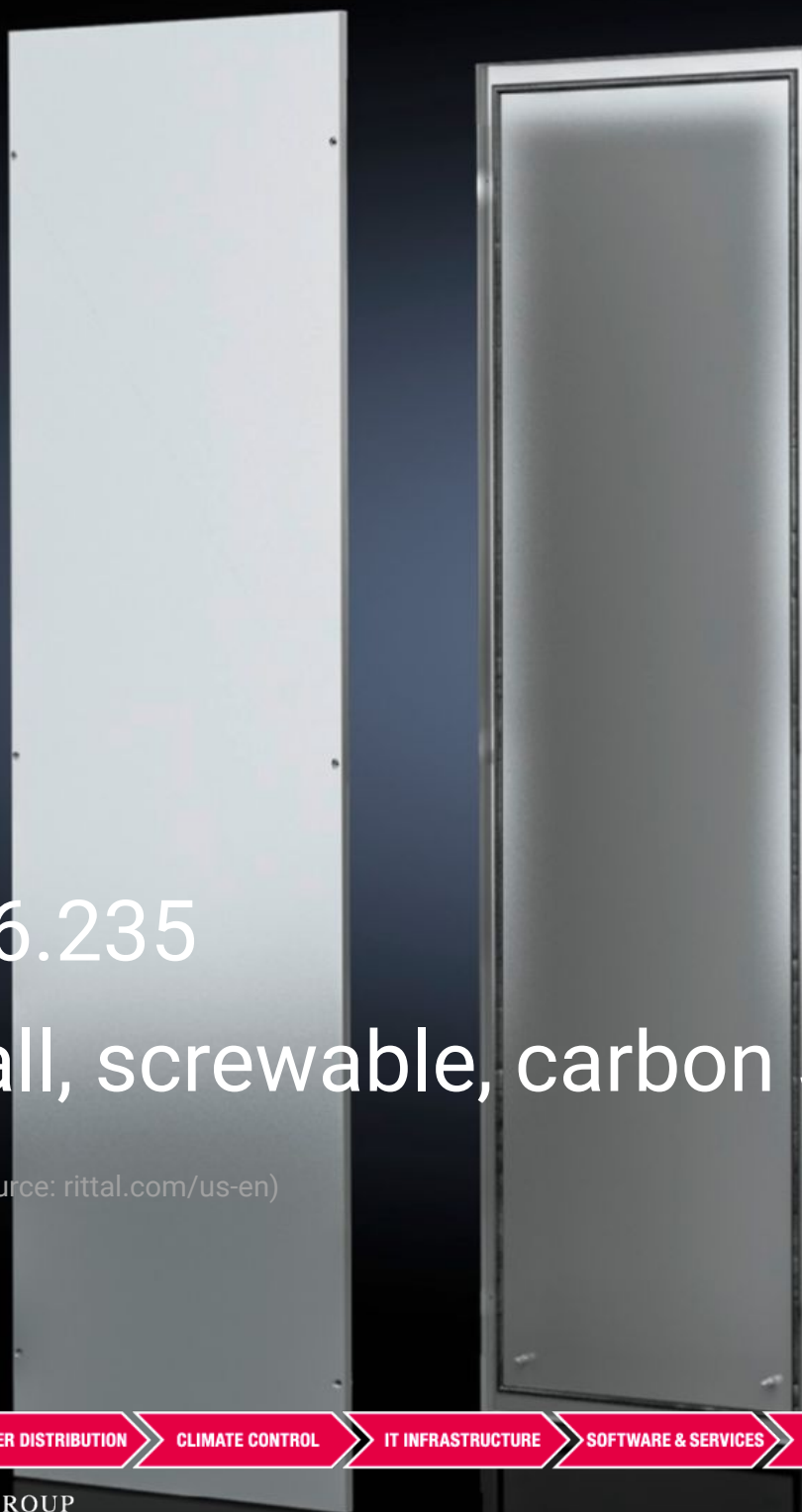

TS 8106.235

Side wall, screwable, carbon steel

State: 8/18/2025 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



TS 8106.235 - Side wall, screwable, carbon steel for TS, TS IT

Side panels, screw-fastened, sheet steel, for TS.

Features

| | |
|-------------------------------------|---|
| Model No. | TS 8106.235 |
| Benefits | Automatic potential equalization and higher EMC protection thanks to enclosure panel holders with grounding insert Easy positioning with the location aid Grounding bolt with contact surface |
| Material | Carbon steel, 1.5 mm |
| Surface finish | Dipcoat-primed, powder-coated on the outside |
| Color | RAL 7035 |
| Supply includes | Assembly components |
| Note | Enclosure panel holders may optionally be fitted from the inside or outside of the enclosure. Area available for population: External dimension – 100 mm |
| Suitable for | Enclosure type: TS TS IT Height: 2,000 mm Depth: 600 mm Enclosure type: TS TS IT Height: 78.7 " Depth: 23.6 " |
| Protection category IP to IEC 60529 | IP 55 |
| Base material | Carbon steel |
| Packaging unit | 2 pc(s). |
| Net weight | 28 |
| Gross weight | 29.2 |

Features

| | |
|-----------------------|---------------|
| Customs tariff number | 94039910 |
| EAN | 4028177205260 |
| E-Number Sweden | E7282533 |
| ETIM 9 | EC002524 |
| ECLASS 8.0 | 27182101 |

Approvals

| | |
|--------------|------------------------------|
| Explanations | Declaration of conformity UK |
|--------------|------------------------------|