


# Rittal – The System.

Faster – better – everywhere.

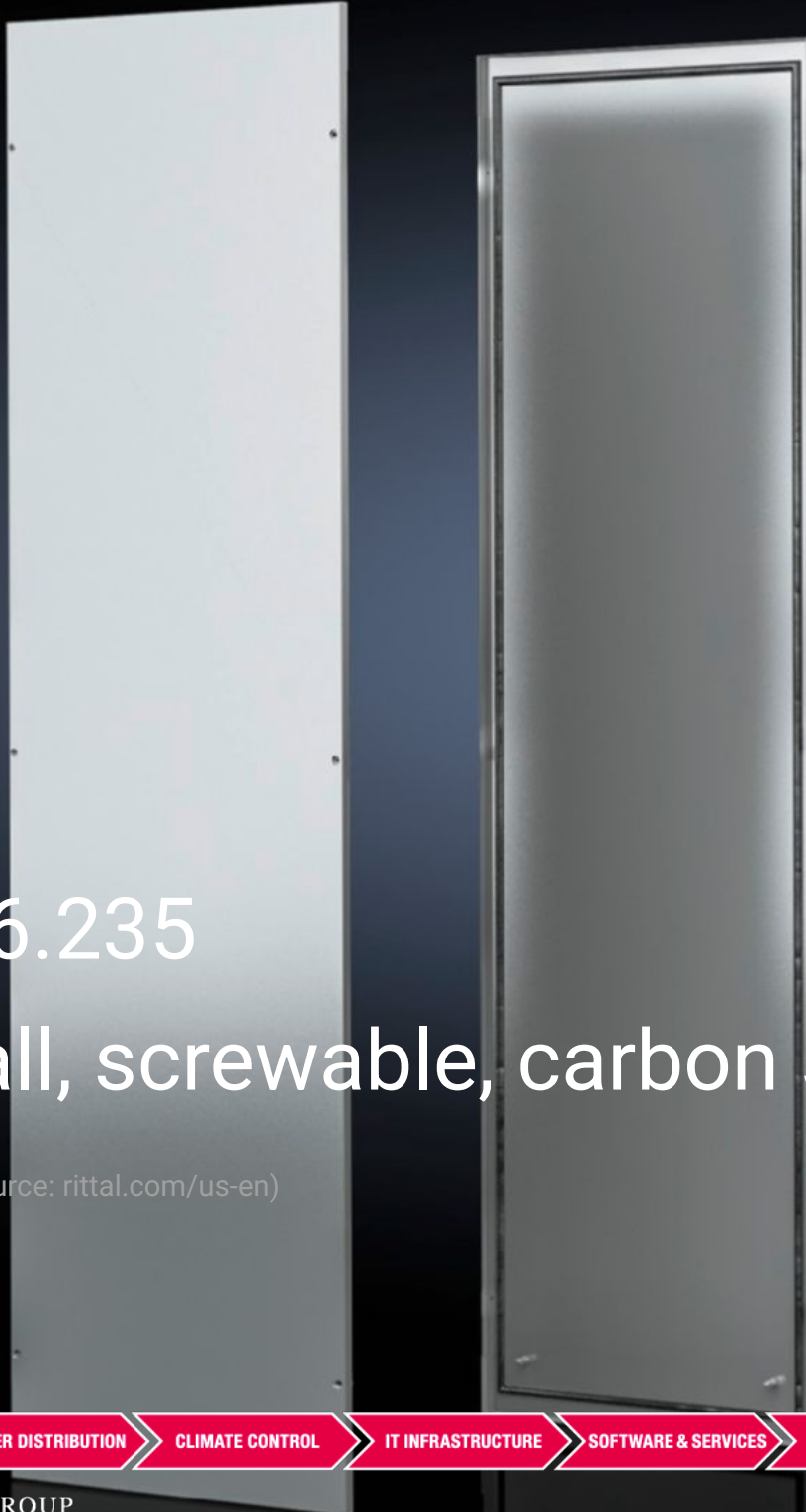

## TS 8106.235

## Side wall, screwable, carbon steel

State: 5/22/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# TS 8106.235 - Side wall, screwable, carbon steel for TS, TS IT

Side panels, screw-fastened, sheet steel, for TS.

## Features

Model No.	TS 8106.235
Benefits	Automatic potential equalization and higher EMC protection thanks to enclosure panel holders with grounding insert Easy positioning with the location aid Grounding bolt with contact surface
Material	Carbon steel, 1.5 mm
Surface finish	Dipcoat-primed, powder-coated on the outside
Color	RAL 7035
Supply includes	Assembly components
Note	Enclosure panel holders may optionally be fitted from the inside or outside of the enclosure. Area available for population: External dimension – 100 mm
Suitable for	Enclosure type: TS TS IT Height: 2,000 mm Depth: 600 mm Enclosure type: TS TS IT Height: 78.7 “ Depth: 23.6 “
Protection category IP to IEC 60529	IP 55
Base material	Carbon steel
Packaging unit	2 pc(s).
Net weight	28 kg
Gross weight	29.2 kg

# Features

---

Customs tariff number	94039910
ETIM 9	EC002524
ECLASS 8.0	27182101
Product description	TS Side panel, screw-fastened, for TS, TS IT, for HxD: 2000x600 mm, Sheet steel, RAL 7035

# Approvals

---

Explanations	Declaration of conformity UK
--------------	------------------------------