


Rittal – The System.

Faster – better – everywhere.

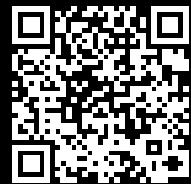

TS 8602.600

Base/plinth components, front and rear, 200 mm

State: 2/16/2026 (Source: rittal.com/us-en)



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

TS 8602.600 - Base/plinth components, front and rear, 200 mm Carbon steel, for TS, TS IT, SE, CM, TP, PC, IW, TE

Base/Plinth component consisting of one trim panel and two pre-assembled corner pieces. On 200 mm high base/plinth components, one trim panel is in two parts to allow for cable entry.

Features

| | |
|---------------------|---|
| Model No. | TS 8602.600 |
| Version | Solid |
| Product description | Base/Plinth component consisting of one trim panel and two pre-assembled corner pieces. On 200 mm high base/plinth components, one trim panel is in two parts to allow for cable entry. |
| Material | Base/plinth components: Carbon steel Cover caps: Plastic |
| Surface finish | Spray-finished |
| Color | RAL 7022 Cover caps: RAL 9005 |
| Supply includes | 2 base/plinth components 4 cover caps Assembly components |
| Dimensions | Height: 200 mm Height: 7.87 " |

Features

| | |
|-----------------------|--|
| Suitable for | Enclosure type: TS: = 600 mm Enclosure type: SE Enclosure type: CM Enclosure type: TP Enclosure type: PC Enclosure type: IW Enclosure type: TS IT Enclosure type: TS: = 23.6 “ Enclosure type: SE Enclosure type: CM Enclosure type: TP Enclosure type: PC Enclosure type: IW Enclosure type: TS IT |
| Packaging unit | 2 pc(s). |
| Net weight | 6.32 |
| Gross weight | 6.963 |
| Customs tariff number | 94039910 |
| EAN | 4028177208612 |
| ECLASS 8.0 | 27182003 |