


**Rittal – The System.**

Faster – better – everywhere.

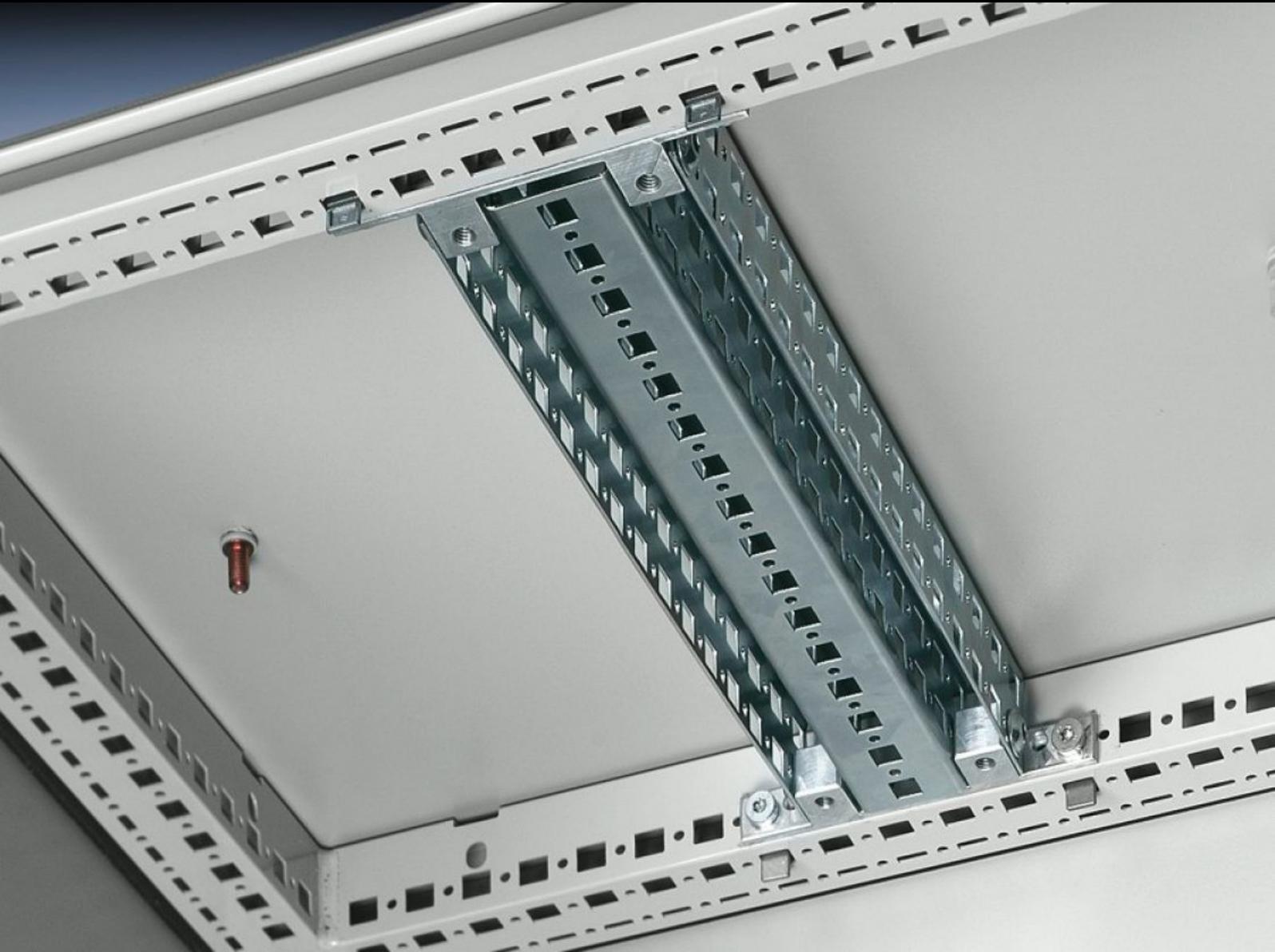

**TS 8612.650**

**TS Mounting Chassis, 45 x 88 mm**

State: 6/1/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# TS 8612.650 - TS Mounting Chassis, 45 x 88 mm

Mounted directly on internal surfaces (e.g. roof) to support heavy assemblies. Mounted on the side or rear, the enclosure can then be screw-fastened securely to the machine.



## Features

Model No.	TS 8612.650
Version	For the inner mounting level
Product description	Mounted directly on internal surfaces (e.g. roof) to support heavy assemblies. Mounted on the side or rear, the enclosure can then be screw-fastened securely to the machine. The double profile with 11 rows of holes provides many additional options for interior configuration.
Material	Carbon steel
Surface finish	Zinc-plated
Supply includes	Assembly components
Installation options	On the vertical and horizontal TS, VX SE enclosure section
Suitable for	Enclosure type: the inner mounting level Width/depth: 500 mm Enclosure type: the inner mounting level Width/depth: 19.7 "
Packaging unit	2 pc(s).
Net weight	2.6 kg
Gross weight	2.611 kg
Customs tariff number	73269098

# Features

---

ETIM 9	EC002625
ECLASS 8.0	27189234
Product description	TS TS punched section without mounting flange, 45 x 88 mm, for inner mounting level: for WD: 500 mm

---