


Rittal – The System.

Faster – better – everywhere.

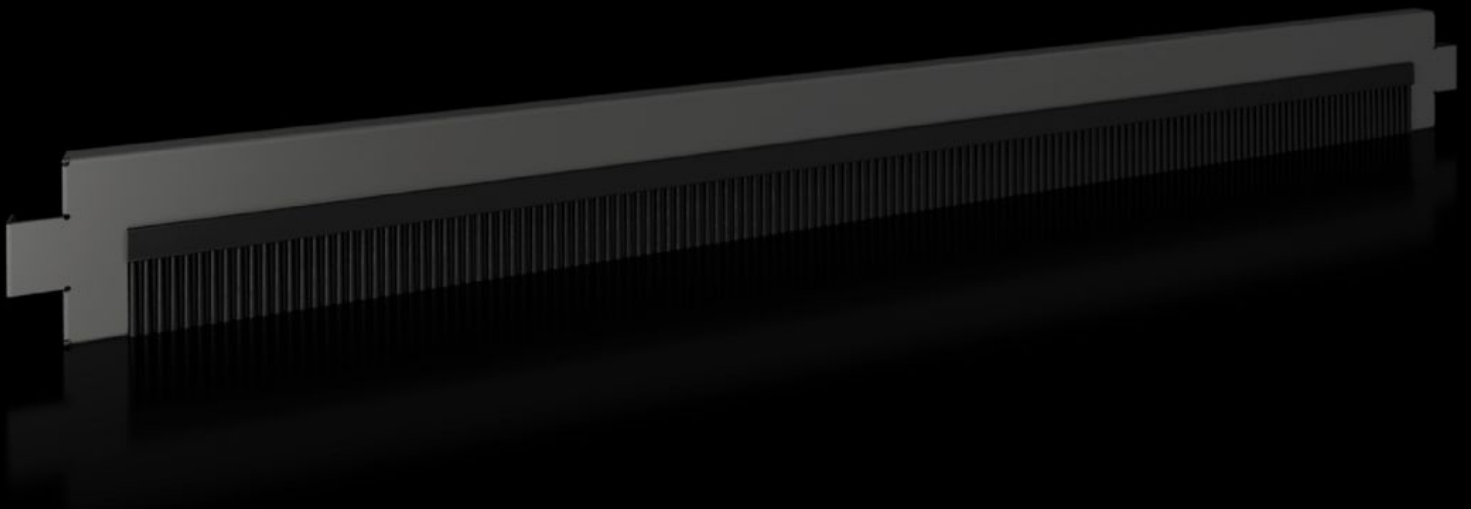

VX 8620.095

Base/Plinth Trim Panels with Brush Strip

State: 5/23/2026 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



VX 8620.095 - Base/Plinth Trim Panels with Brush Strip

For VX base/plinth systems

The 100 mm high base/plinth trim panels can be used in the depth or the width for cable entry into the base/plinth. The trim panels can also be used in 200 mm high base/plinths and they can be combined with other 100 mm high trim panels.

Features

| | |
|---------------------------------|---|
| Model No. | VX 8620.095 |
| Product description | For cable entry into the base/plinth. If the base/plinth height is 200 mm, one or two trim panels with brush strips can optionally be used. The VX base/plinth system's complete symmetry allows the trim panels with brush strips to be mounted either at the front, rear or side of the base/plinth corner piece. |
| Material | Base/plinth trims: Carbon steel Brush strip: Plastic, self-extinguishing |
| Color | RAL 9005 |
| Supply includes | Assembly components |
| Dimensions | Height: 100 mm Height: 3.94 " |
| Suitable for | Width/depth: 1,200 mm Width/depth: 47.2 " |
| Type rating according to UL 50E | Type 1, 12 |
| Weight/packaging unit | 2.8 kg 6.2 lb. |
| Packaging unit | 2 pc(s). |
| Net weight | 2.5 kg |
| Gross weight | 2.8 kg |
| Customs tariff number | 94039910 |
| ETIM 9 | EC000721 |
| ECLASS 8.0 | 27182003 |

Features

Product description

VX Base/plinth trim panel, with brush strip, for W/D: 1200 mm

Approvals

Approvals

UL + C-UL - FTTA