




# Rittal – The System.

Faster – better – everywhere.

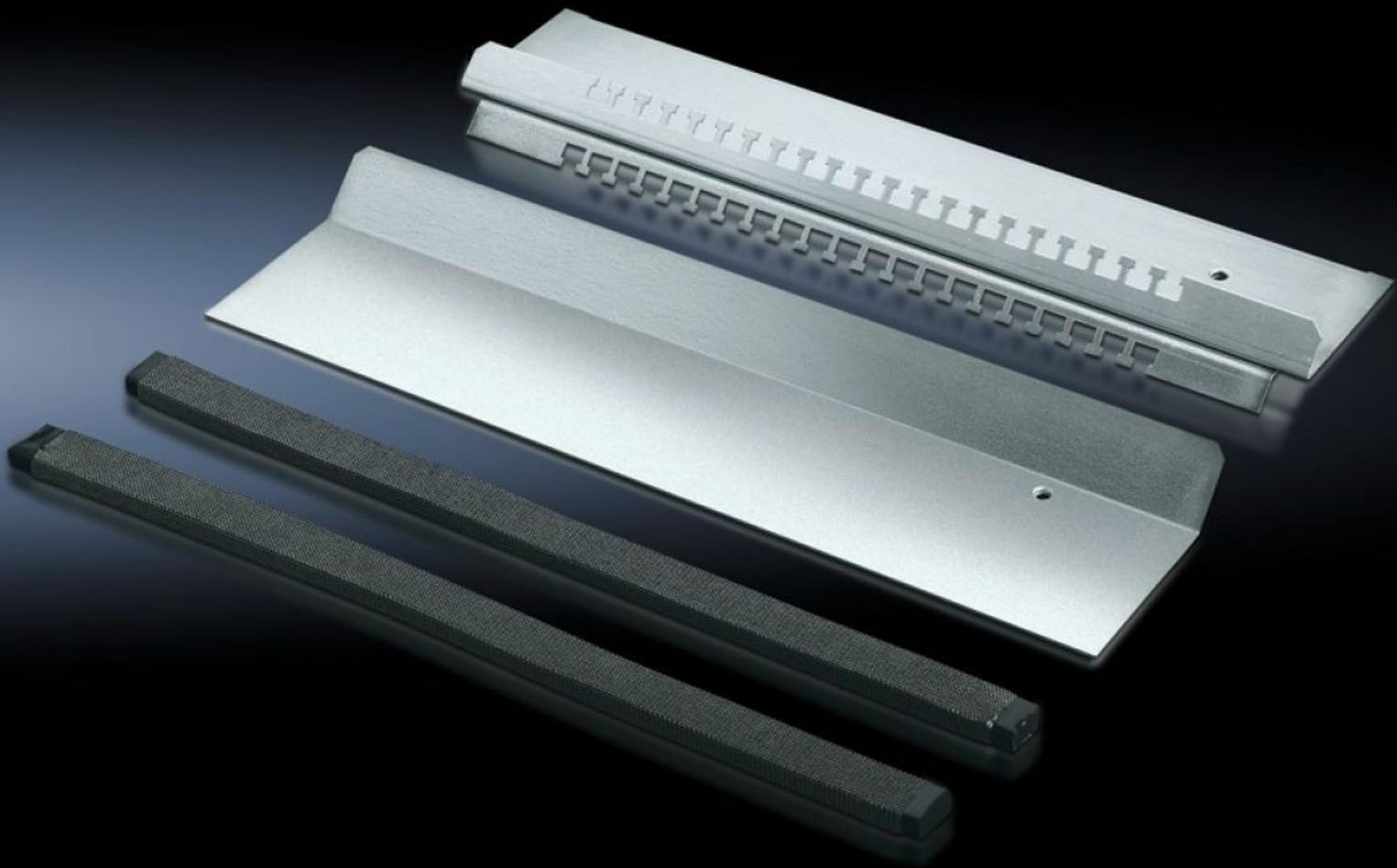

## TS 8800.660 EMC Base Plate

State: 1/30/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))



FRIEDHELM LOH GROUP

# TS 8800.660 - EMC Base Plate

For shielded cables with max. 20 mm diameter in combination with standard base plates.

## Features

Model No.	TS 8800.660
Product description	For shielded cables with max. 20 mm diameter. Combined EMC contacting and cable fixation provide low-impedance contact between the cable shield and the base plate. For all 400, 500, 600 and 800 mm deep enclosures, in combination with standard base plates.
Material	Carbon steel
Surface finish	Zinc-plated
Supply includes	Cable management rail with T-head punching 1 sliding base plate 2 EMC seals
Suitable for	Enclosure type: TS Width: = 600 mm Enclosure type: TS Width: = 23.6 "
Note	No standard-compliant IP protection rating possible
Packaging unit	1 pc(s).
Net weight	1.7
Gross weight	1.8
Customs tariff number	94039910
EAN	4028177214880
ETIM 9	EC002620
ECLASS 8.0	27189261