


Rittal – The System.

Faster – better – everywhere.

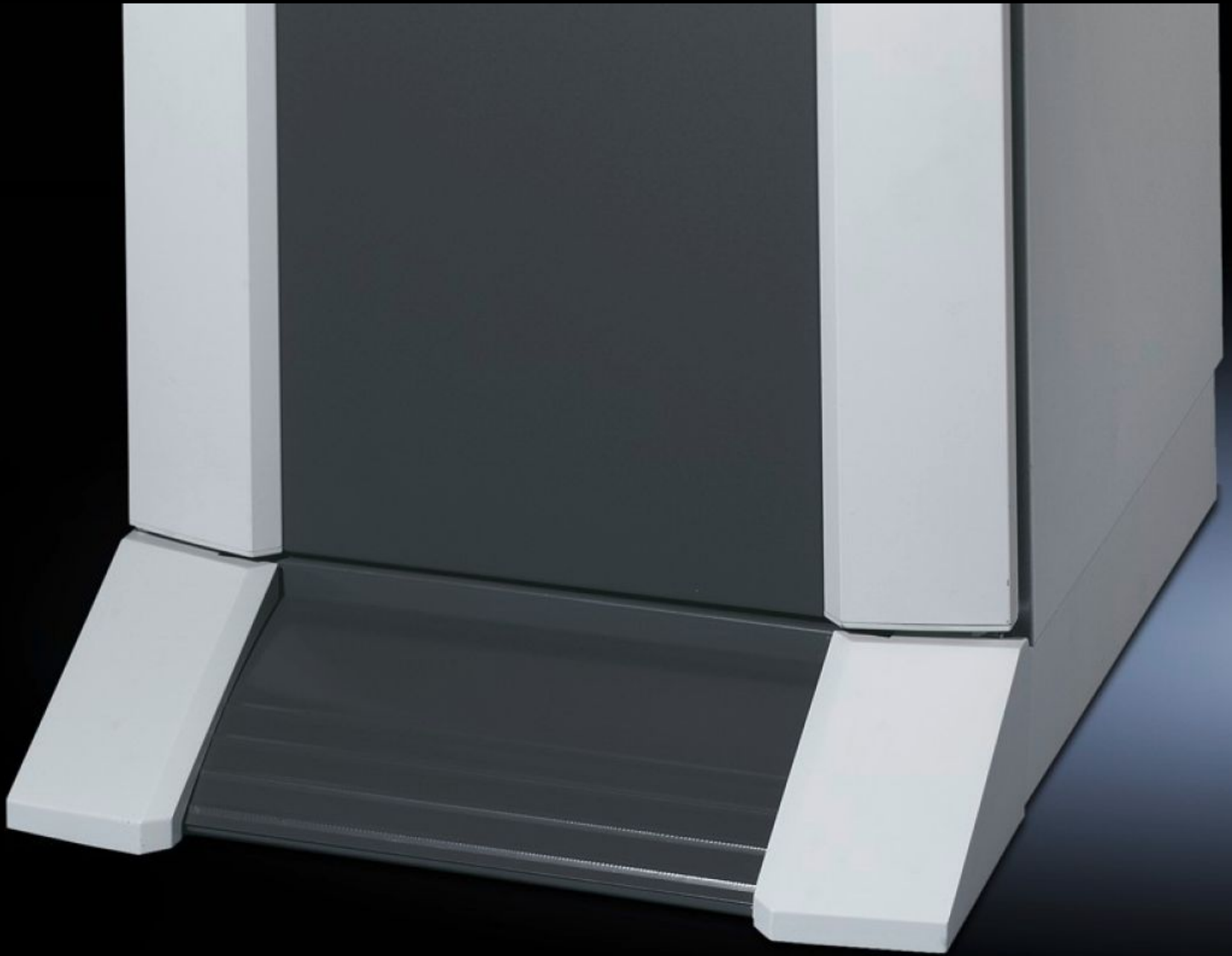

PC 8800.920

Base/plinth, stationary

State: 6/6/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



PC 8800.920 - Base/plinth, stationary for PC, IW

Design matches the housing, height 100 mm, with front projection.

Features

Model No.	PC 8800.920
Product description	Design matches the housing, with front projection.
Material	Carbon steel, 2.0 mm
Color	RAL 7035 Design component, front: RAL 7015
Supply includes	1 design component, front 1 base/plinth component, rear 2 base/plinth trim panels, side
Dimensions	Height: 100 mm Height: 3.94 "
Suitable for	Enclosure type: PC IW Width: = 600 mm Depth: = 600 mm Enclosure type: PC IW Width: = 23.6 " Depth: = 23.6 "
Suitable for depth	600 mm 23.6 "
Packaging unit	1 pc(s).
Net weight	11.92 kg
Gross weight	13.02 kg
PCF/VE (cradle-to-gate)	49.5 kg CO2 eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared
Customs tariff number	94039910

Features

ETIM 9	EC000721
ECLASS 8.0	27182003
Product description	PC Base/plinth, stationary, for PC, IW, for D: 600 mm, H: 100 mm, Sheet steel
