


# Rittal – The System.

Faster – better – everywhere.

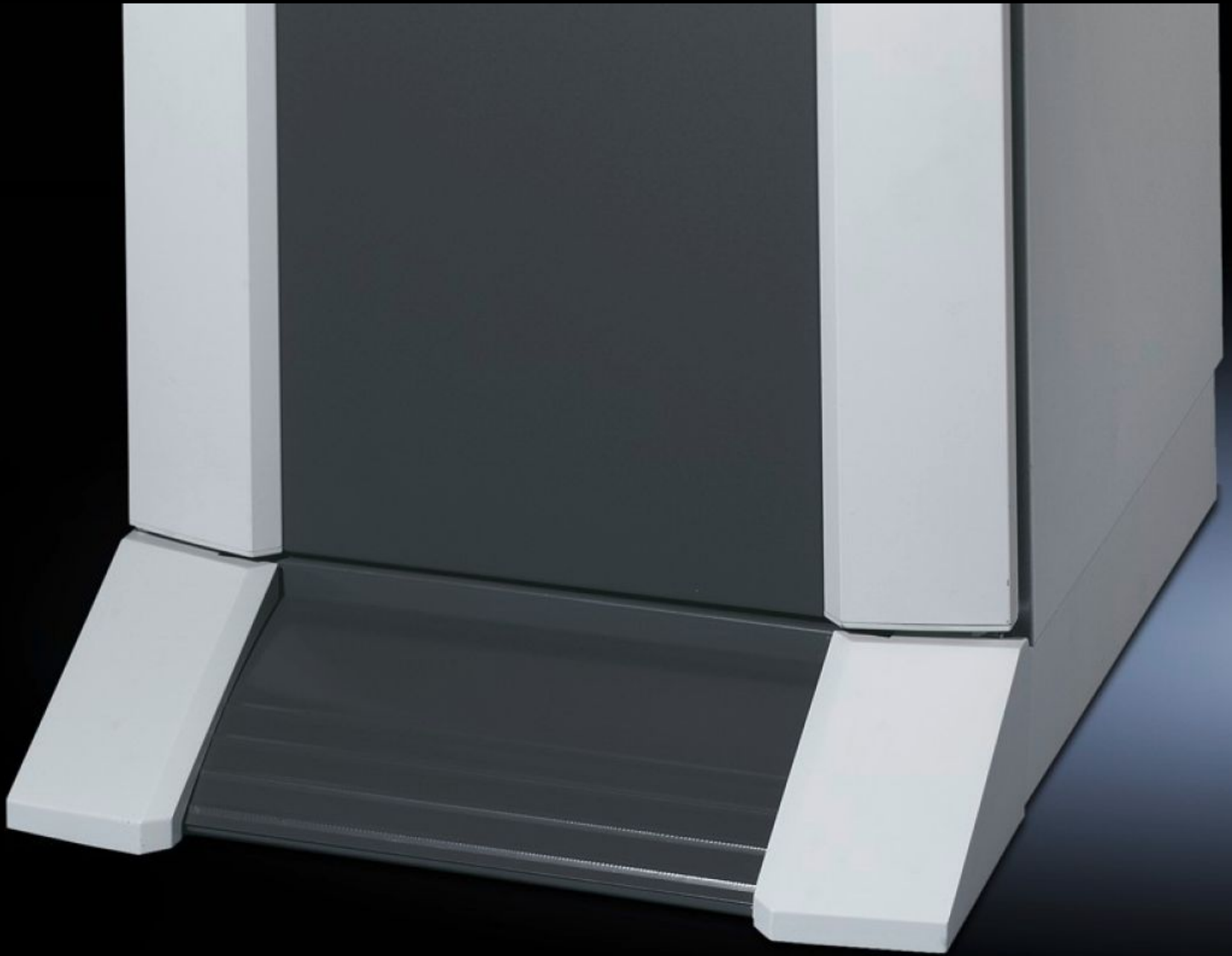

## PC 8800.920

## Base/plinth, stationary

State: 7/9/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# PC 8800.920 - Base/plinth, stationary for PC, IW

Design matches the housing, height 100 mm, with front projection.

## Features

Model No.	PC 8800.920
Product description	Design matches the housing, with front projection.
Material	Carbon steel, 2.0 mm
Color	RAL 7035 Design component, front: RAL 7015
Supply includes	1 design component, front 1 base/plinth component, rear 2 base/plinth trim panels, side
Dimensions	Height: 100 mm Height: 3.94 "
Suitable for	Enclosure type: PC IW Width: = 600 mm Depth: = 600 mm Enclosure type: PC IW Width: = 23.6 " Depth: = 23.6 "
Suitable for depth	600 mm 23.6 "
Packaging unit	1 pc(s).
Net weight	11.92 kg
Gross weight	13.02 kg
PCF/VE (cradle-to-gate)	49.5 kg CO2 eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared
Customs tariff number	94039910

# Features

---

ETIM 9	EC000721
ECLASS 8.0	27182003
Product description	PC Base/plinth, stationary, for PC, IW, for D: 600 mm, H: 100 mm, Sheet steel

---