


Rittal – The System.

Faster – better – everywhere.

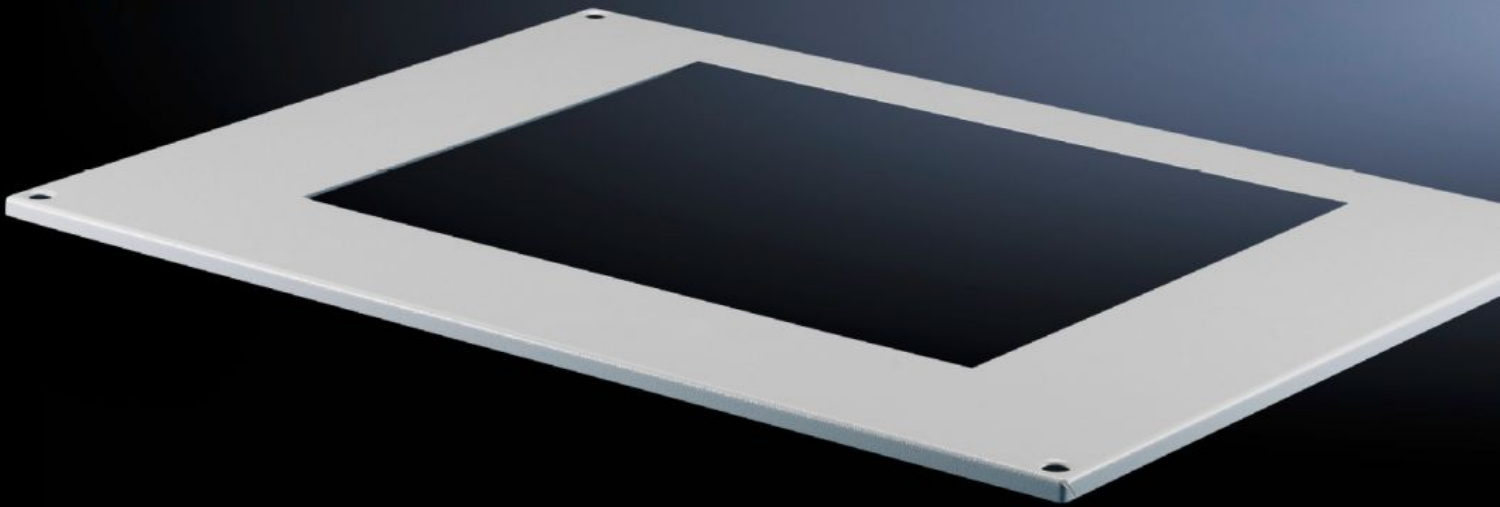

TS 8801.340 TS Roof Plates

State: 5/12/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



TS 8801.340 - TS Roof Plates

Features

Model No.	TS 8801.340
Product description	For installing roof-mounted cooling units and roof-mounted air/water heat exchangers. The cut-outs in the roof plate are arranged so that the roof-mounted cooling units are centered on the enclosure.
Benefits	Simple, fast mounting
Material	Carbon steel
Color	RAL 7035
Supply includes	Assembly components
Mounting cut-out	Width:692 mm Depth:392 mm Width:27.2 " Depth:15.4 "
Distance cut-out to back	57.8 mm 2.28 "
Note	When mounting cooling units on the roof plate 8801.310 there may be a collision with the transportation eyebolts of the enclosure. For this reason, roof fastening screws are supplied loose with the roof plates. Attachment to the roof plate 8801.310 is from the inside using metal brackets and retaining clamps.
Suitable for Model No.	3386.... 3387....
Dimensions	Width: 767.5 mm Height: 13 mm Depth: 567.5 mm Width: 30.2 " Height: 0.51 " Depth: 22.3 "

Features

Suitable for	Enclosure type: TS Width: = 800 mm Depth: = 600 mm Enclosure type: TS Width: = 31.5 " Depth: = 23.6 "
Packaging unit	1 pc(s).
Net weight	4.3 kg
Gross weight	4.5 kg
Customs tariff number	73269098
ETIM 9	EC000744
ECLASS 8.0	27182405
Product description	TS roof plates, for WD: 800 x 600 mm
