


Rittal – The System.

Faster – better – everywhere.

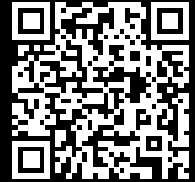

DK 9055.412 Monitor/Keyboard Unit

State: 4/28/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 9055.412 - Monitor/Keyboard Unit with 17" TFT display and VGA/DVI connection

1 U chassis with 17" TFT display, English or German keyboard layout, with telescopic slides.



Features

Model No.	DK 9055.412
Benefits	Analog and digital video port Cables are safely routed in the energy chain Lockable at the front Simple, one-man installation.
Color	RAL 9005
Supply includes	Monitor/Keyboard Unit, 1 U VGA cable DVI cable USB Cable Schuko power cable with 17" TFT display and VGA/DVI connection 2 PS/2 cables Keyboard with integral touchpad
Rated operating voltage	100 V - 240 V, 1~, 50 Hz/60 Hz
Max. power consumption with closed monitor unit	1 W
Max. power consumption in operation	32 W

Features

Interfaces	VGA (D-SUB HD 15-pole) DVI 1 x USB PS/2
Connector (type)	Non-heating apparatus connector C14
Layout	US English
Note on Model No.:	Delivery times on request.
Dimensions	Width: 482.6 mm Depth: 680 mm Width: 19 " Depth: 26.8 "
Operating temperature range	5 °C...45 °C 41 °F...113 °F
Installation dimensions	Installation depth (min.): 680 mm Installation depth (max.): 850 mm Installation depth (min.): 26.8 " Installation depth (max.): 33.5 "
Display features	Diagonal: 432 mm (17") Format: 4 : 3 Contrast ratio: Contrast ratio approx. 1000:1 Display brightness: 350 cd/m ² Display resolution: 1280 x 1024 pixels Number of colors: 16,700,000
Packaging unit	1 pc(s).
Net weight	15.5 kg
Gross weight	16.5 kg
Customs tariff number	85286200
ETIM 9	EC001428
ECLASS 8.0	19200201
Product description	DK Monitor/keyboard unit, WHD: 482.6 mm (19")x1 Ux680 mm, 100-240 V, 1~, 50/60 Hz, US-english, RAL 9005

Approvals

Explanations

Declaration of conformity