
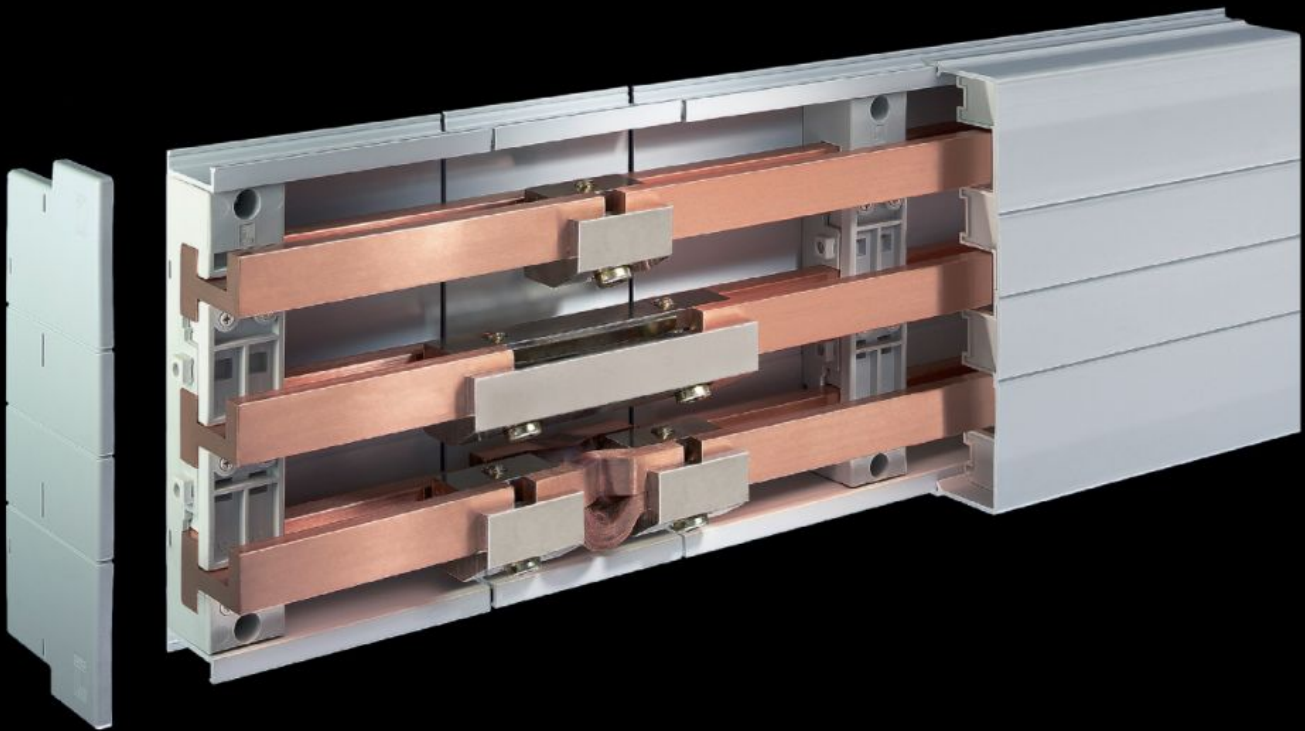


Rittal – The System.

Faster – better – everywhere.

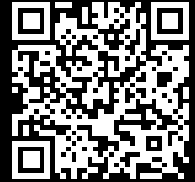

SV 9342.004 PLS Busbar Supports

State: 4/28/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SV 9342.004 - PLS Busbar Supports

For PLS special busbars 800 A/1600 A, 3-pole and 4-pole

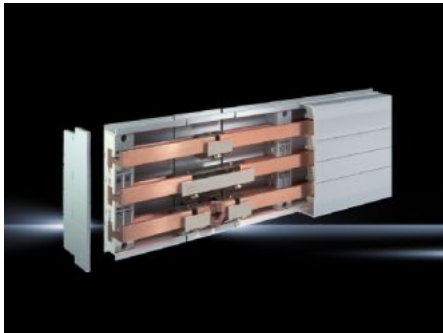

Features

Model No.	SV 9342.004
Material	Polyamide Fire protection corresponding to UL 94-V0
Color	RAL 7035
Rated operating voltage	1000 V, 3~
Electrical UL ratings (SCCR)	65 kA - 480 V, support spacing 250 mm, busbars PLS 1600, circuit breaker max. 1200A, DIVQ/7
Note on Model No.:	The use of a base tray is required for UL applications. UL approval only applies in conjunction with AC application
Busbar support design	PLS 1600 PLUS
Number of poles	4-pole
Suitable for busbars	PLS 1600
Suitable for Model No.	3516.000 3527.000 3528.010 3529.000
With internal attachment	Yes
Center-to-center spacing of busbars	60 mm
Approvals	UL

Features

Packaging unit	4 pc(s).
Net weight	2.2 kg
Gross weight	2.321 kg
Customs tariff number	85469010
ETIM 9	EC001166
ECLASS 8.0	27400607
Product description	SV Busbar support, PLS 1600, 4-pole, 60 mm bar centre distance, UL design

Approvals

Approvals	ABS Lloyds Register of Shipping UL + C-UL (listed)
Explanations	Declaration of conformity Declaration of conformity UK