


Rittal – The System.

Faster – better – everywhere.

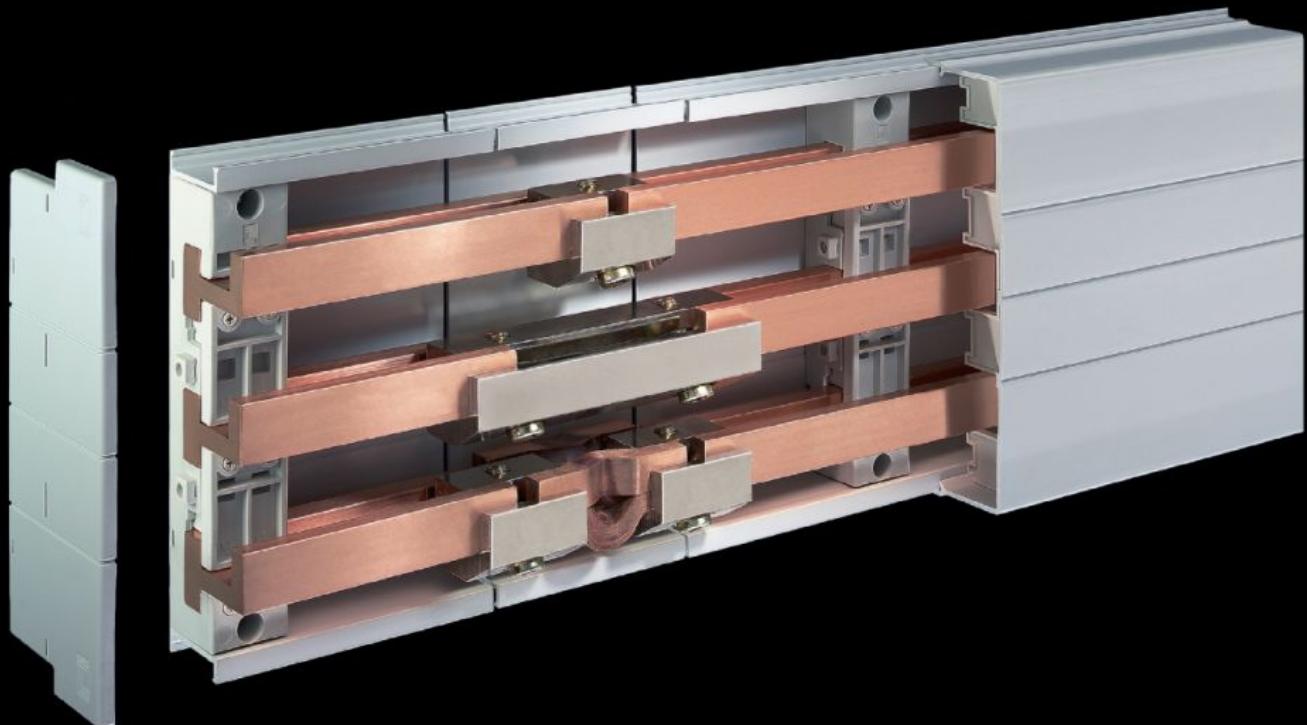

SV 9342.004

PLS Busbar Supports

State: 2/3/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SV 9342.004 - PLS Busbar Supports

For PLS special busbars 800 A/1600 A, 3-pole and 4-pole.

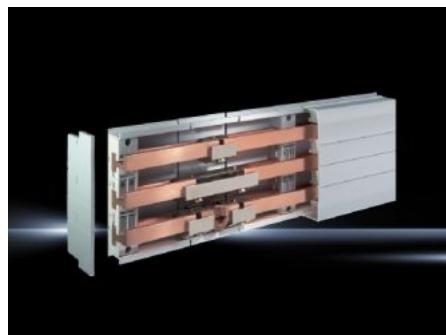

Features

Model No.	SV 9342.004
Material	Polyamide Fire protection corresponding to UL 94-V0
Color	RAL 7035
Rated operating voltage	1000 V, 3~
Electrical UL ratings (SCCR)	65 kA - 480 V, support spacing 250 mm, busbars PLS 1600, circuit breaker max. 1200A, DIVQ/7
Note on Model No.:	The use of a base tray is required for UL applications. UL approval only applies in conjunction with AC application
Busbar support design	PLS 1600 PLUS
Number of poles	4-pole
Suitable for busbars	PLS 1600
Suitable for Model No.	3516.000 3527.000 3528.010 3529.000
With internal attachment	Yes
Center-to-center spacing of busbars	60 mm
Approvals	UL

Features

Packaging unit 4 pc(s).

Net weight 2.2

Gross weight 2.321

Customs tariff number 85469010

EAN 4028177536760

ETIM 9 EC001166

ECLASS 8.0 27400607

Approvals

Approvals ABS
Lloyds Register of Shipping
UL + C-UL (listed)

Explanations Declaration of conformity
Declaration of conformity UK