


Rittal – The System.

Faster – better – everywhere.

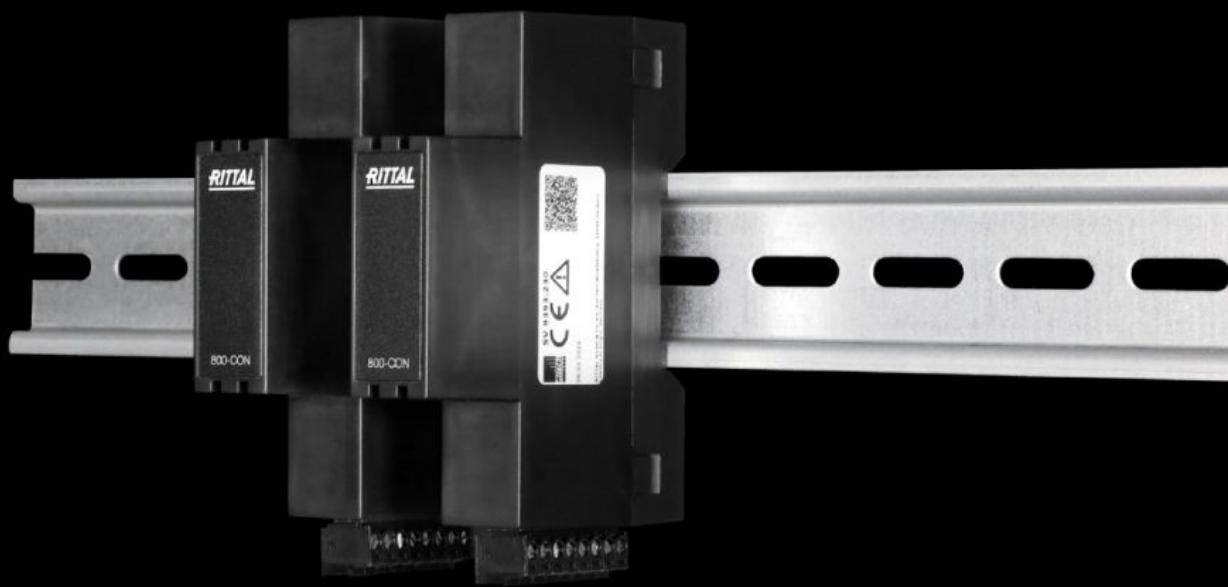

SV 9393.230

Connection module

State: 1/30/2026 (Source: ittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SV 9393.230 - Connection module REM 800-CON

For connecting remotely located measuring points.

Features

Model No.	SV 9393.230
Product description	For connecting remotely located measuring points.
Supply includes	2 connection modules 2 bus connectors (left/right) 2 shield terminals 2 screw terminals 2 end brackets
Operating temperature range	-10 °C...55 °C 14 °F...131 °F
Storage temperature range	-25 °C...70 °C -13 °F...158 °F
Ambient humidity (non-condensing)	5...25 %
Contamination level	2
Protection category IP to IEC 60529	IP 20
For support rail assembly	Yes
Connection of round conductors, fine wire with wire end ferrule	0.2 - 1.5 mm ²
Connection of round conductors, fine wire without wire end ferrule	0.2 - 1.5 mm ²
Connection of round conductors, single-wire	0.2 - 1.5 mm ²
Connection of round conductors, multi-wire	0.2 - 1.5 mm ²
Connection for round conductor	AWG 16 - 24
Packaging unit	2 pc(s).

Features

Net weight	0.36
Gross weight	0.366
Customs tariff number	85389099
EAN	4028177984974

Approvals

Explanations Declaration of conformity