


# Rittal – The System.

Faster – better – everywhere.

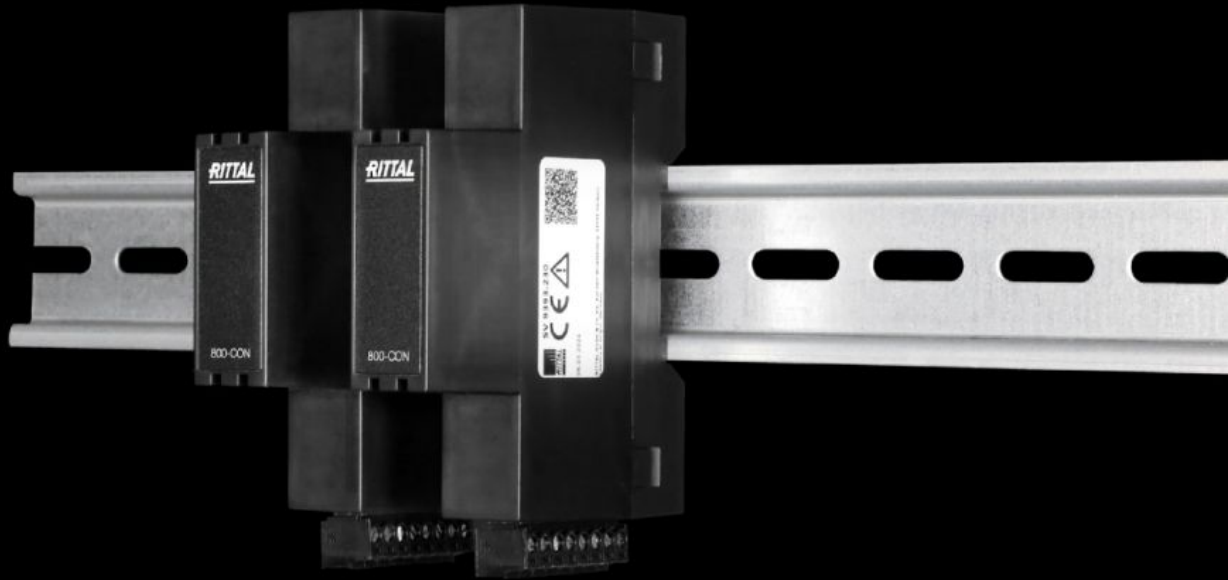

## SV 9393.230 Connection module

State: 4/19/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SV 9393.230 - Connection module REM 800-CON

For connecting remotely located measuring points.

## Features

Model No.	SV 9393.230
Product description	For connecting remotely located measuring points.
Supply includes	2 connection modules 2 bus connectors (left/right) 2 shield terminals 2 screw terminals 2 end brackets
Operating temperature range	-10 °C...55 °C 14 °F...131 °F
Storage temperature range	-25 °C...70 °C -13 °F...158 °F
Ambient humidity (non-condensing)	5...25 %
Contamination level	2
Protection category IP to IEC 60529	IP 20
For support rail assembly	Yes
Connection of round conductors, fine wire with wire end ferrule	0.2 - 1.5 mm <sup>2</sup>
Connection of round conductors, fine wire without wire end ferrule	0.2 - 1.5 mm <sup>2</sup>
Connection of round conductors, single-wire	0.2 - 1.5 mm <sup>2</sup>
Connection of round conductors, multi-wire	0.2 - 1.5 mm <sup>2</sup>
Connection for round conductor	AWG 16 - 24
Packaging unit	2 pc(s).

# Features

---

Net weight	0.36 kg
Gross weight	0.366 kg
Customs tariff number	85389099
Product description	SV connection module REM 800-CON

# Approvals

---

Explanations	Declaration of conformity
--------------	---------------------------