


Rittal – The System.

Faster – better – everywhere.

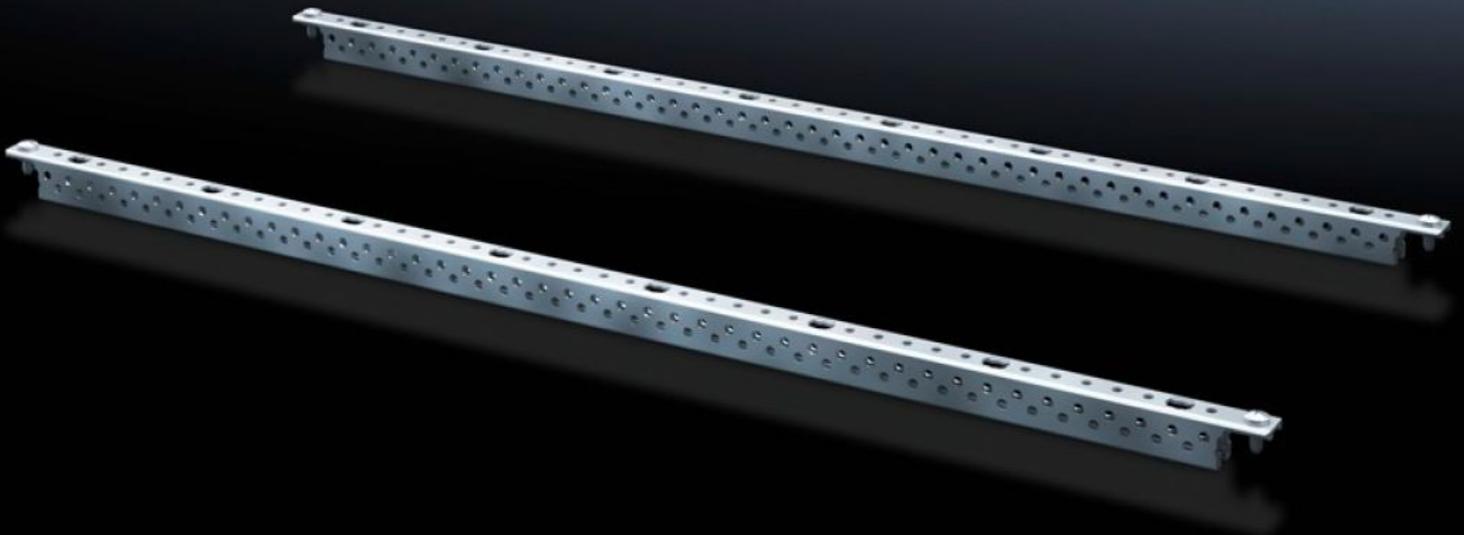

SV 9666.753 Mounting angle ISV

State: 4/29/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SV 9666.753 - Mounting angle ISV for AX

For vertical sub-division of the support frame in AX/AE enclosures.

Features

| | |
|-------------------------------------|--|
| Model No. | SV 9666.753 |
| Product description | For vertical sub-division of the support frame in the enclosure. |
| Material | Carbon steel |
| Surface finish | Zinc-plated |
| Dimensions | Height: 450 mm Height: 17.7 " |
| Size | Height units (U) @ 150 mm: 3 |
| Packaging unit | 2 pc(s). |
| Net weight | 0.46 kg |
| Gross weight | 0.5 kg |
| PCF/VE (cradle-to-gate) | 2.3 kg CO2 eq (Cat B) |
| Information regarding the PCF class | Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared |
| Customs tariff number | 39269097 |
| ETIM 9 | EC002270 |
| ECLASS 8.0 | 27400613 |
| Product description | SV Mounting angle (ISV), 3 U (450 mm), for AE |