


Rittal – The System.

Faster – better – everywhere.

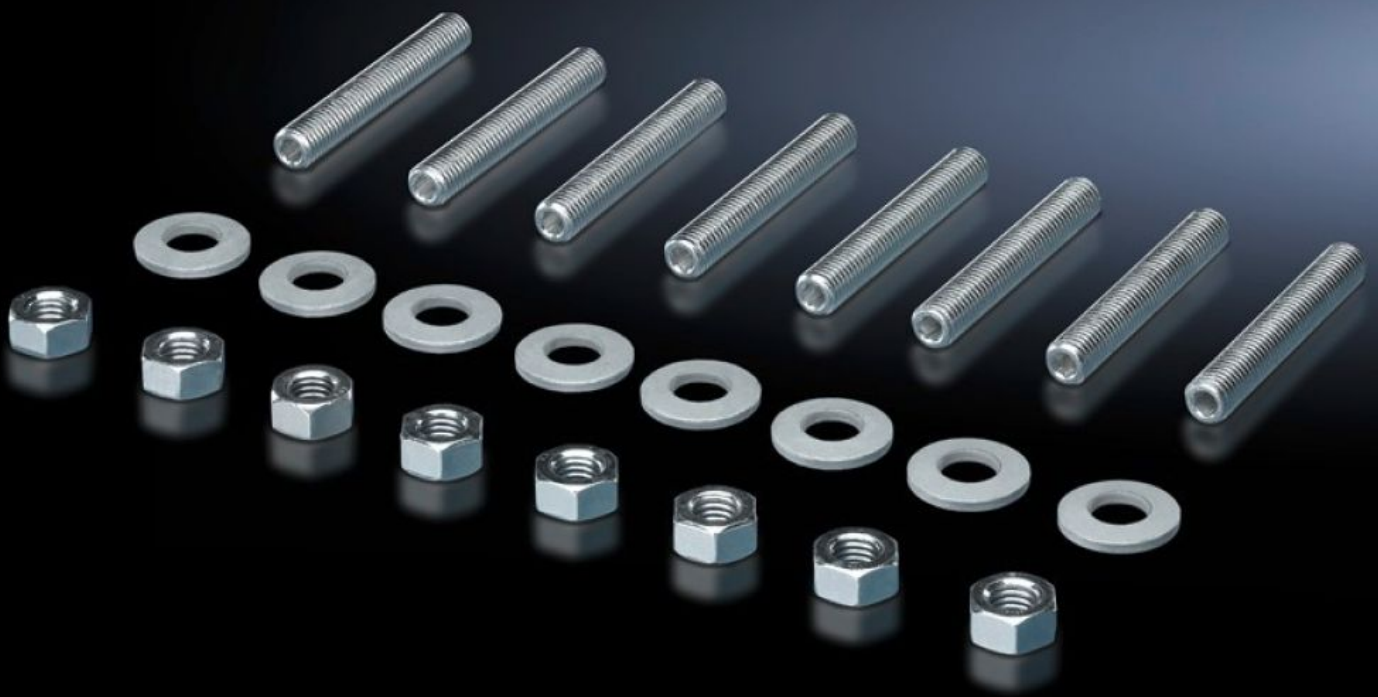

SV 9676.983 Threaded Bolts

State: 5/21/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SV 9676.983 - Threaded Bolts for sliding blocks and sliding nuts

For fastening connection components such as cable lugs.

Features

Model No.	SV 9676.983
Product description	For individual connection options.
Material	Steel
Supply includes	Assembly components
Suitable for busbars	Maxi-PLS 60
Dimensions	Thread: M12 Thread length: 60 mm Thread: M12 Thread length: 2.36 "
Packaging unit	8 pc(s).
Net weight	0.4 kg
Gross weight	0.536 kg
Customs tariff number	73181535
ETIM 9	EC002349
ECLASS 8.0	23110302
Product description	SV Threaded bolt, M12, L: 60 mm

Approvals

Approvals	UL + C-UL (listed)
-----------	--------------------