


Rittal – The System.

Faster – better – everywhere.

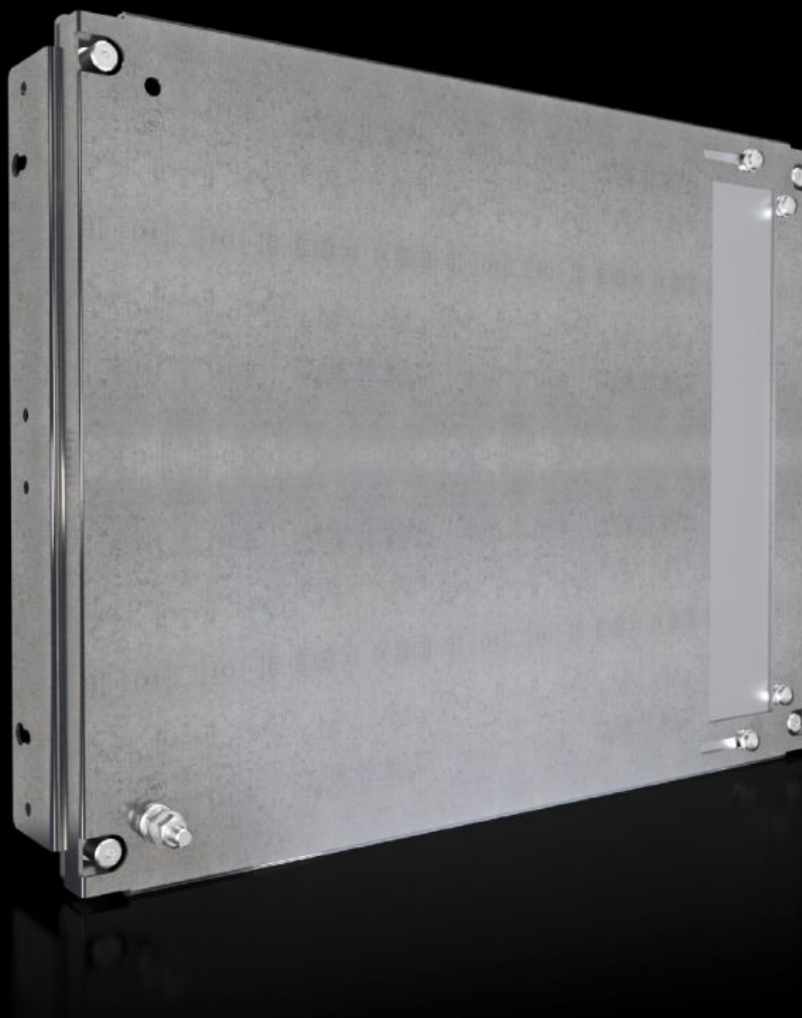

SV 9683.564 Partial Mounting Plate

State: 5/21/2024 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SV 9683.564 - Partial Mounting Plate for compartment side panel

With or without cable entry, for direct attachment to compartment side panel.

Features

Model No.	SV 9683.564
Version	with insulating material gland
Product description	For direct attachment to the compartment side panel for internal compartmentalization. Universal internal installation with switchgear and control devices. Creation of additional mounting levels. In combination with compartment dividers and side panels, internal partitioning in accordance with Form 1 to 4 is possible.
Material	Carbon steel, 2 mm
Surface finish	Zinc-plated
Supply includes	Angle brackets and assembly components
For compartment height	400 mm 15.7 "
Dimensions	Width: 502 mm Height: 393 mm Width: 19.8 " Height: 15.5 "
Suitable for	Width: = 600 mm Width: = 23.6 "
Packaging unit	1 pc(s).
Weight/packaging unit	4.7 kg 10.4 lb.
Customs tariff number	94039910
EAN	4028177935075
ETIM 7.0	EC001900
ECLASS 8.0	27400613

Approvals

Explanations	Declaration of conformity
	Declaration of conformity UK