


# Rittal – The System.

Faster – better – everywhere.

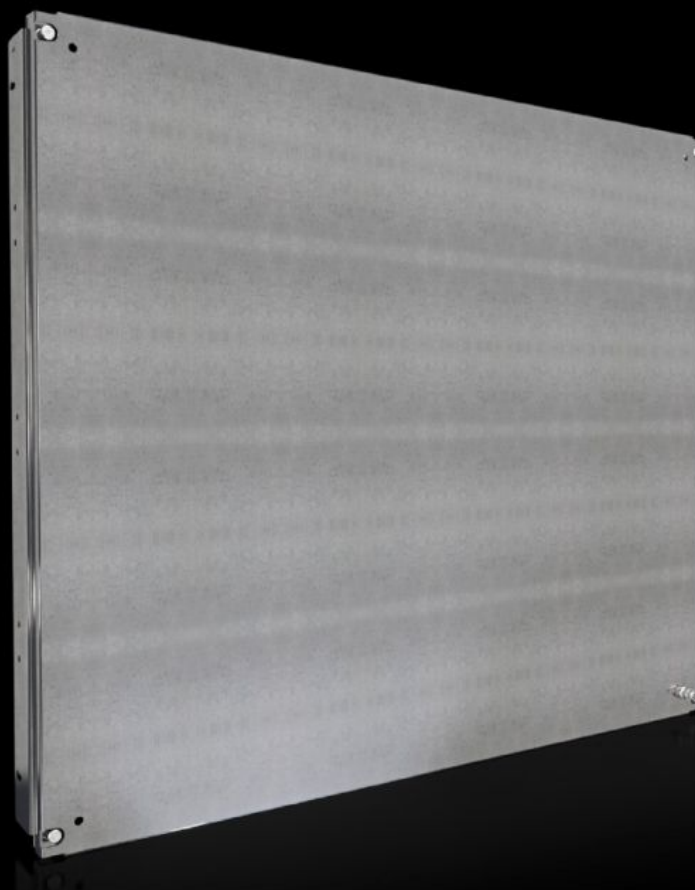

## SV 9683.608

### Partial Mounting Plate

State: 5/16/2024 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SV 9683.608 - Partial Mounting Plate for compartment side panel

With or without cable entry, for direct attachment to compartment side panel.

## Features

Model No.	SV 9683.608
Version	Solid
Product description	For direct attachment to the compartment side panel for internal compartmentalization. Universal internal installation with switchgear and control devices. Creation of additional mounting levels. In combination with compartment dividers and side panels, internal partitioning in accordance with Form 1 to 4 is possible.
Material	Carbon steel, 2 mm
Surface finish	Zinc-plated
Supply includes	Angle brackets and assembly components
For compartment height	800 mm 31.5 "
Dimensions	Width: 902 mm Height: 793 mm Width: 35.5 " Height: 31.2 "
Suitable for	Width: = 1,000 mm Width: = 39.4 "
Packaging unit	1 pc(s).
Weight/packaging unit	12.76 kg 28.1 lb.
Customs tariff number	94039910
EAN	4028177935310
ETIM 7.0	EC001900
ECLASS 8.0	27400613

# Approvals

---

Explanations	Declaration of conformity
	Declaration of conformity UK