


Rittal – The System.

Faster – better – everywhere.

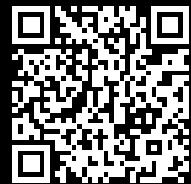

SV 9683.628

Partial Mounting Panel

State: 2/13/2026 (Source: ittal.com/us-en)



FRIEDHELM LOH GROUP

SV 9683.628 - Partial Mounting Panel for compartment side panel

With or without cable entry, for direct attachment to compartment side panel.

Features

Model No.	SV 9683.628
Version	Solid
Product description	For direct attachment to the compartment side panel for internal compartmentalization. Universal internal installation with switchgear and control devices. Creation of additional mounting levels. In combination with compartment dividers and side panels, internal partitioning in accordance with Form 1 to 4 is possible.
Material	Carbon steel, 2 mm
Surface finish	Zinc-plated
Supply includes	Angle brackets and assembly components
For compartment height	800 mm 31.5 "
Dimensions	Width: 1,102 mm Height: 793 mm Width: 43.4 " Height: 31.2 "
Suitable for	Width: = 1,200 mm Width: = 47.2 "
Packaging unit	1 pc(s).
Net weight	17.48
Gross weight	17.98
PCF/VE (cradle-to-gate)	68.5 kg CO ₂ eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared
Customs tariff number	94039910

Features

EAN 4028177935112

ETIM 9 EC000213

ECLASS 8.0 27400613

Approvals

Explanations Declaration of conformity UK