
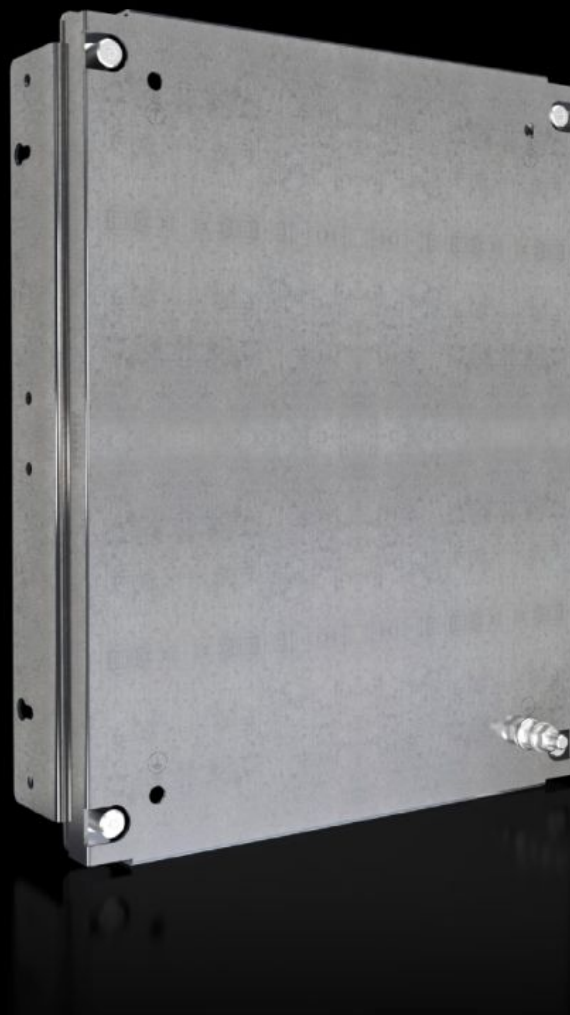


# Rittal – The System.

Faster – better – everywhere.

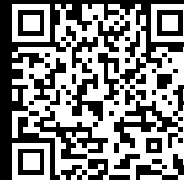

## SV 9683.644

## Partial Mounting Panel

State: 6/8/2025 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SV 9683.644 - Partial Mounting Panel for compartment side panel

With or without cable entry, for direct attachment to compartment side panel.

## Features

Model No.	SV 9683.644
Version	Solid
Product description	For direct attachment to the compartment side panel for internal compartmentalization. Universal internal installation with switchgear and control devices. Creation of additional mounting levels. In combination with compartment dividers and side panels, internal partitioning in accordance with Form 1 to 4 is possible.
Material	Carbon steel, 2 mm
Surface finish	Zinc-plated
Supply includes	Angle brackets and assembly components
For compartment height	400 mm 15.7 "
Dimensions	Width: 302 mm Height: 393 mm Width: 11.9 " Height: 15.5 "
Suitable for	Width: = 400 mm Width: = 15.7 "
Packaging unit	1 pc(s).
Net weight	3.1
Gross weight	3.46
PCF per pack (cradle-to-gate)	13.2 kg CO2 eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	94039910

# Features

EAN	4028177935143
ETIM 9	EC000213
ECLASS 8.0	27400613

# Approvals

Explanations	Declaration of conformity UK
--------------	------------------------------