


Rittal – The System.

Faster – better – everywhere.

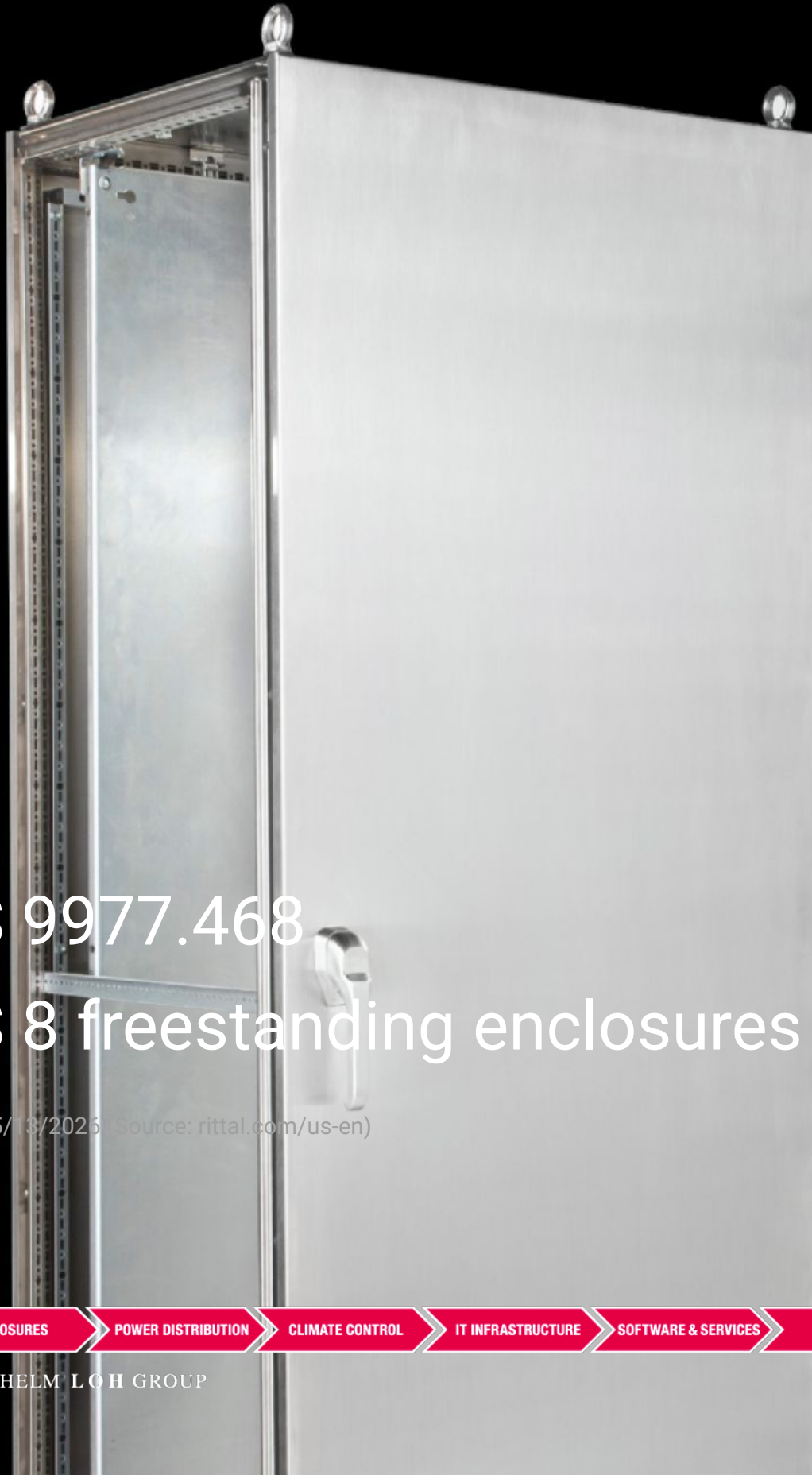

TS 9977.468 TS 8 freestanding enclosures

State: 5/13/2025 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



TS 9977.468 - TS 8 freestanding enclosures Stainless steel

Baying systems TS 8 with mounting plate. Protection category IP 66 (UL Type 4X). Manufactured in stainless steel 1.4404 (AISI 316L) Enclosure widths include 600 and 800 mm.



Features

Model No.	TS 9977.468
Material	Enclosure frame: Stainless steel 1.4404 (AISI 316L), 1.5 mm Roof: Stainless steel 1.4404 (AISI 316L), 1.5 mm, exterior brushed Door: Stainless steel 1.4404 (AISI 316L), 2.0 mm, exterior brushed Rear panel: Stainless steel 1.4404 (AISI 316L), 1.5 mm, exterior brushed Gland plate: Stainless steel 1.4404 (AISI 316L), 2.5 mm
Surface finish	Enclosure frame and base plates: Uncoated Door, roof and rear panel: Exterior brushed, grain size 400 Mounting panel: Zinc-plated
Supply includes	Gland plate Padlockable handle

Features

Dimensions	Width: 800 mm Height: 2,000 mm Depth: 500 mm Width: 31.5 " Height: 78.7 " Depth: 19.7 "
------------	--

Packaging unit	1 pc(s).
----------------	----------

Net weight	315.994 lb
------------	------------

Gross weight	315.994 lb
--------------	------------

Customs tariff number	9403200082
-----------------------	------------

Approvals

Approvals	UL + C-UL (listed)
-----------	--------------------