


# Rittal – The System.

Faster – better – everywhere.

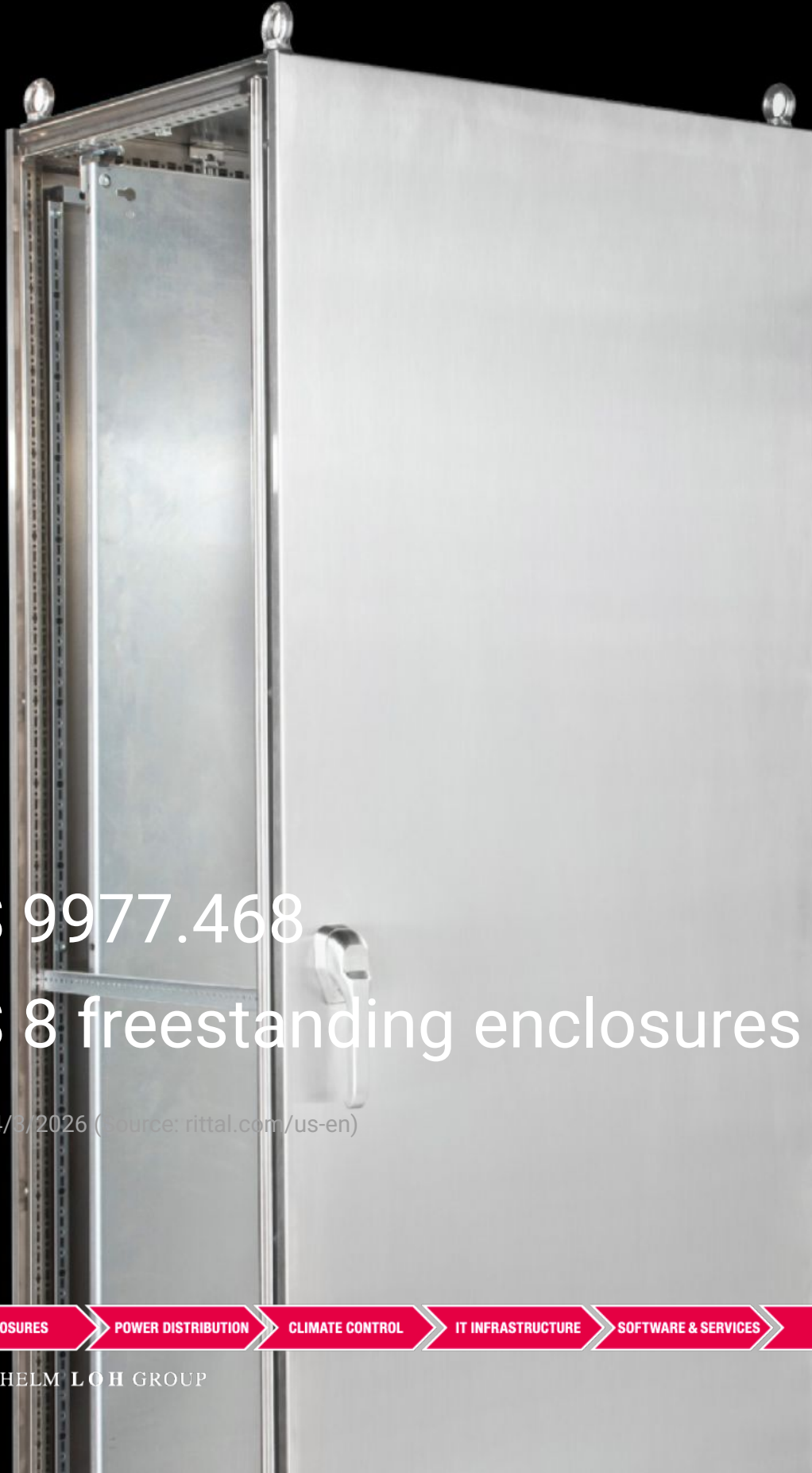

## TS 9977.468 TS 8 freestanding enclosures

State: 4/3/2026 (source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# TS 9977.468 - TS 8 freestanding enclosures Stainless steel

Baying systems TS 8 with mounting plate. Protection category IP 66 (UL Type 4X). Manufactured in stainless steel 1.4404 (AISI 316L) Enclosure widths include 600 and 800 mm.



## Features

Model No.	TS 9977.468
Material	Enclosure frame: Stainless steel 1.4404 (AISI 316L), 1.5 mm Roof: Stainless steel 1.4404 (AISI 316L), 1.5 mm, exterior brushed Door: Stainless steel 1.4404 (AISI 316L), 2.0 mm, exterior brushed Rear panel: Stainless steel 1.4404 (AISI 316L), 1.5 mm, exterior brushed Gland plate: Stainless steel 1.4404 (AISI 316L), 2.5 mm
Surface finish	Enclosure frame and base plates: Uncoated Door, roof and rear panel: Exterior brushed, grain size 400 Mounting panel: Zinc-plated
Supply includes	Gland plate Padlockable handle

# Features

---

Dimensions	Width: 800 mm Height: 2,000 mm Depth: 500 mm Width: 31.5 " Height: 78.7 " Depth: 19.7 "
------------	--

---

Packaging unit	1 pc(s).
----------------	----------

---

Net weight	315.994 lb
------------	------------

---

Gross weight	315.994 lb
--------------	------------

---

Customs tariff number	9403200082
-----------------------	------------

---

# Approvals

---

Approvals	UL + C-UL (listed)
-----------	--------------------