


# Rittal – The System.

Faster – better – everywhere.

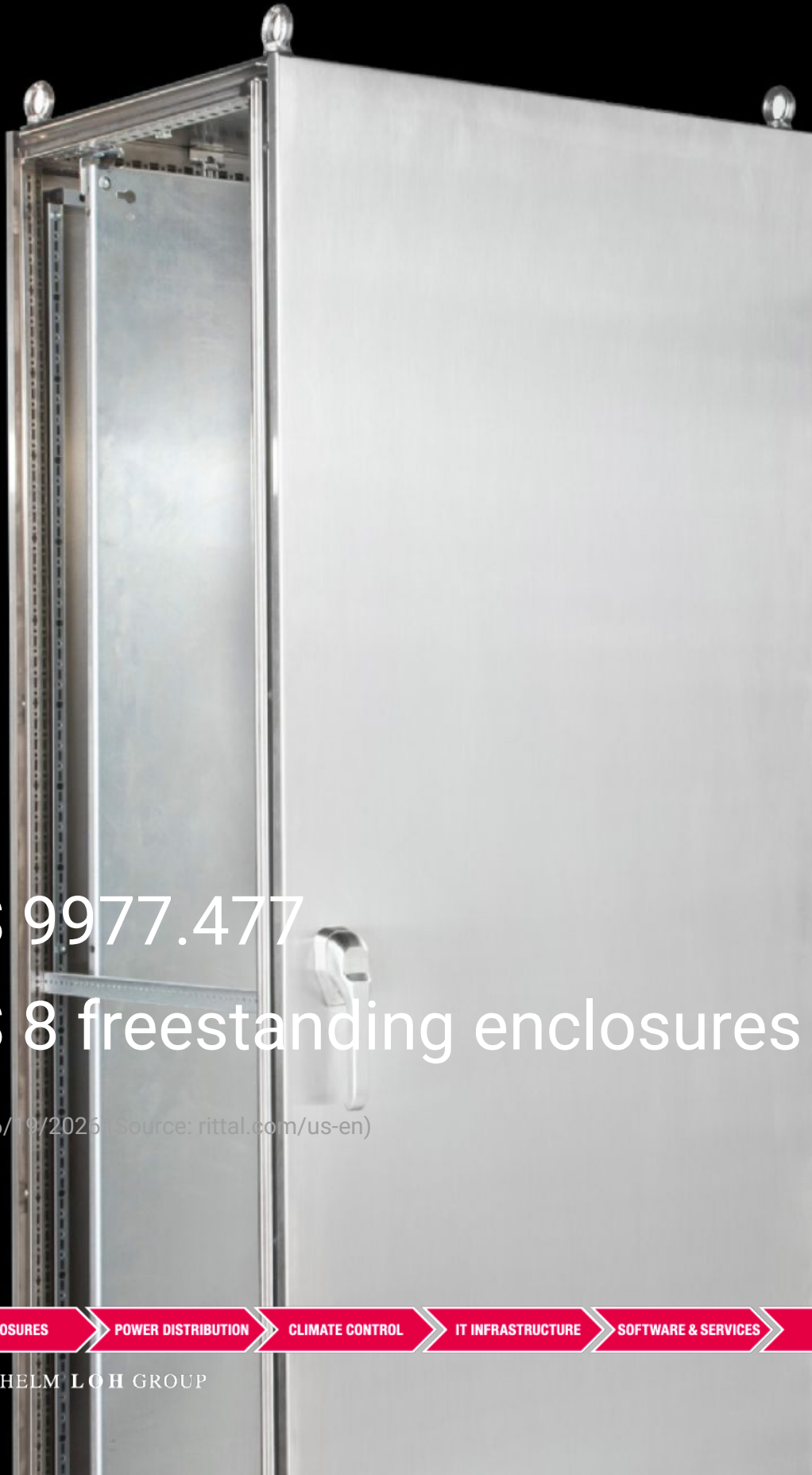

## TS 9977.477 TS 8 freestanding enclosures

State: 6/19/2025 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# TS 9977.477 - TS 8 freestanding enclosures Stainless steel

Baying systems TS 8 with mounting plate. Protection category IP 66 (UL Type 4X). Manufactured in stainless steel 1.4404 (AISI 316L) Enclosure widths include 600 and 800 mm.



## Features

Model No.	TS 9977.477
Material	Enclosure frame: Stainless steel 1.4404 (AISI 316L), 1.5 mm Roof: Stainless steel 1.4404 (AISI 316L), 1.5 mm, exterior brushed Door: Stainless steel 1.4404 (AISI 316L), 2.0 mm, exterior brushed Rear panel: Stainless steel 1.4404 (AISI 316L), 1.5 mm, exterior brushed Gland plate: Stainless steel 1.4404 (AISI 316L), 2.5 mm
Surface finish	Enclosure frame and base plates: Uncoated Door, roof and rear panel: Exterior brushed, grain size 400 Mounting panel: Zinc-plated
Supply includes	Gland plate Padlockable handle

# Features

---

Dimensions	Width: 600 mm Height: 1,800 mm Depth: 600 mm Width: 23.6 " Height: 70.9 " Depth: 23.6 "
------------	--

---

Packaging unit	1 pc(s).
----------------	----------

---

Gross weight	400 lb
--------------	--------

---

Customs tariff number	9403200082
-----------------------	------------

---

# Approvals

---

Approvals	UL + C-UL (listed)
-----------	--------------------