

Rittal – The System.

Faster – better – everywhere.



IT 9982.200 TS IT Pro

State: 7/22/2024 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



IT 9982.200 - TS IT Pro

TS IT Pro configured for ready deployment. Black. Enclosures are complete with depth adjustable 19" EIA rails, casters, baying kit and locking front and rear perforated doors. Available in a range of sizes with or without sidewalls.

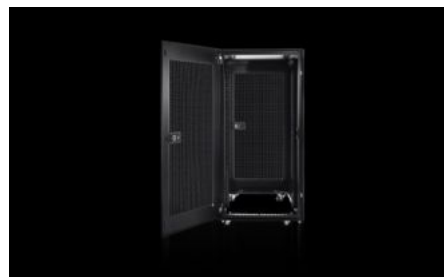

Features

| | |
|---------------------|--|
| Model No. | IT 9982.200 |
| Product description | Ships complete with perforated single front and rear doors keyed alike, leveling feet, casters, roof with cable access. |
| Material | Carbon steel |
| Surface finish | Enclosure frame: Dipcoat-primed Interior installation: Dipcoat-primed Doors and roof: Dipcoat-primed, powder coated |
| Basic color | RAL 9005 |
| Color | Interior installation: RAL 9005 Enclosure frame and panels: RAL 9005 |
| Supply includes | Perforated steel door at the front and rear (surface area approx. 85% perforated) 130° quick release internal hinges Enclosure frame TS 8 with door and roof plate Installed caster kits Leveling Feet Baying Brackets (4 X 24" and 4 X 600mm) M6 cage nuts (Package of 50) M6 mounting screws (Package of 50) Solid sidewalls, pre-installed |

Features

| | |
|--------------------------------------|--|
| Dimensions | Width: 600 mm Height: 1,200 mm Depth: 1,070 mm Width: 23.6 " Height: 47.2 " Depth: 42.1 " |
| Installation height for components | 24 U |
| Note | The door-opening angle may vary depending on site requirements or applications with side panels |
| Distance between levels as delivered | 745 mm 29.3 " |
| Design of 19" mounting level(s) | Profile rails, 482.6 mm (19") |
| Design doors | Perforated front and rear |
| Packaging unit | 1 pc(s). |
| Weight/packaging unit | 78.52 kg 173.1 lb. |
| UPC-Code | 92998 |

Approvals

| | |
|-----------|----|
| Approvals | UL |
|-----------|----|