

# Rittal – The System.

Faster – better – everywhere.



## IT 9982.200 TS IT Pro

State: 4/19/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# IT 9982.200 - TS IT Pro

TS IT Pro configured for ready deployment. Black. Enclosures are complete with depth adjustable 19" EIA rails, casters, baying kit and locking front and rear perforated doors. Available in a range of sizes with or without sidewalls.

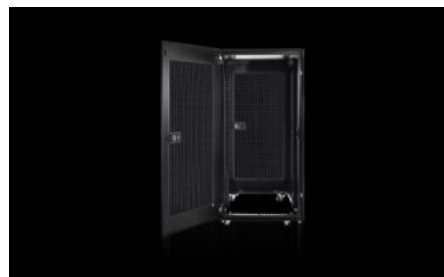

## Features

Model No.	IT 9982.200
Product description	Ships complete with perforated single front and rear doors keyed alike, leveling feet, casters, roof with cable access.
Material	Carbon steel
Surface finish	Enclosure frame: Dipcoat-primed Interior installation: Dipcoat-primed Doors and roof: Dipcoat-primed, powder coated
General color	RAL 9005
Color	Interior installation: RAL 9005 Enclosure frame and panels: RAL 9005
Supply includes	Perforated steel door at the front and rear (surface area approx. 85% perforated) 130° quick release internal hinges Enclosure frame TS 8 with door and roof plate Installed caster kits Leveling Feet Baying Brackets (4 X 24" and 4 X 600mm) M6 cage nuts (Package of 50) M6 mounting screws (Package of 50) Solid sidewalls, pre-installed

# Features

---

Dimensions	Width: 600 mm Height: 1,200 mm Depth: 1,070 mm Width: 23.6 " Height: 47.2 " Depth: 42.1 "
Installation height for components	24 U
Note	The door-opening angle may vary depending on site requirements or applications with side panels
Distance between levels as delivered	745 mm 29.3 "
Design of 19" mounting level(s)	Profile rails, 482.6 mm (19")
Design doors	Perforated front and rear
Packaging unit	1 pc(s).
Gross weight	173.1 lb
Customs tariff number	9403200082

---

# Approvals

---

Approvals	UL
-----------	----