

# Rittal – The System.

Faster – better – everywhere.

## **Wire end ferrules loose – AS 4050.742**

Date : 24.9.2020

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# Wire end ferrules loose – AS 4050.742

created: 24.09.2020 build on [www.rittal.com/si-sl](http://www.rittal.com/si-sl)

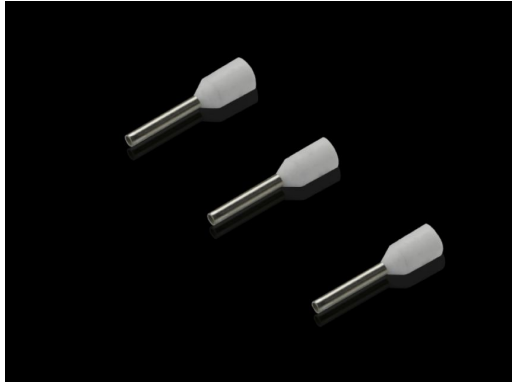

## Product description

<b>Description:</b>	With plastic collar.
<b>Technical specifications:</b>	Heat-resistant to 105 °C
<b>Standards:</b>	AEH DIN 46228
<b>Material:</b>	E-Cu, galvanic tin-plated Plastic collar: Polypropylene
<b>Note:</b>	UL-certified in conjunction with the relevant tools, such as crimping machines.

## Product features

<b>For cross-section:</b>	0,5 mm <sup>2</sup>
<b>AWG:</b>	20
<b>Length:</b>	8 mm
<b>Internal diameter:</b>	2,9 mm
<b>Design:</b>	For manual wire processing (AWG cables/multi-standard cables) and crimping machines 0.5 - 1.5 mm <sup>2</sup> , with extra wide collar
<b>Colour:</b>	White
<b>Colour code:</b>	DIN colour code: yes

<b>For:</b>	Crimping machine L8 manual wire processing
<b>Delivery form:</b>	Loose
<b>Packs of:</b>	500 pc(s).
<b>Weight/pack:</b>	0 kg
<b>Copper weight (kg per piece):</b>	0
<b>EAN:</b>	4028177805101
<b>Customs tariff number:</b>	85369010
<b>ETIM 7.0:</b>	EC000005
<b>ETIM 6.0:</b>	EC000005
<b>eCl@ss 8.0/8.1:</b>	36659290
<b>eCl@ss 6.0/6.1:</b>	36659290
<b>Product description:</b>	Wire end ferrules According to DIN colour code
<b>Approvals</b>	
<b>Approvals:</b>	UR