

Rittal – The System.

Faster – better – everywhere.

Wire end ferrules on a reel – AS 4051.547

Date : 29.9.2020

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



Wire end ferrules on a reel – AS 4051.547

created: 29.09.2020 build on www.rittal.com/si-sl

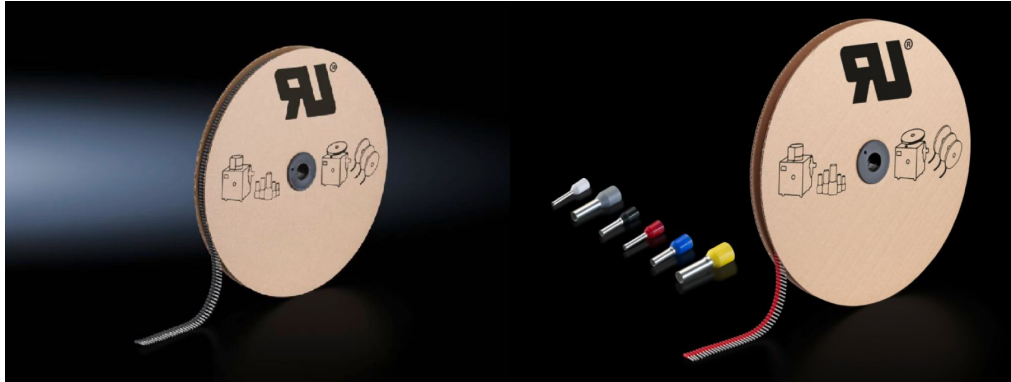

Product description

| | |
|----------------------------------|---|
| Description: | With plastic collar. |
| Technical specifications: | Heat-resistant to 105 °C |
| Standards: | AEH DIN 46228 |
| Material: | E-Cu, galvanic tin-plated Plastic collar: Polypropylene |
| Note: | UL-certified in conjunction with the relevant tools, such as crimping machines. |

Product features

| | |
|---------------------------|--|
| For cross-section: | 1,5 mm ² |
| AWG: | 16 |
| Length: | 10 mm |
| Internal diameter: | 4 mm |
| Design: | for wire processing machines |
| Colour: | Black |
| Colour code: | DIN colour code: yes Multiple colour codes supported: yes |

| | |
|--------------------------------------|--|
| For: | Crimping machine RC |
| Delivery form: | Taped |
| Packs of: | 4000 pc(s). |
| Copper weight (kg per piece): | 0 |
| EAN: | 4028177937956 |
| Customs tariff number: | 85369010 |
| ETIM 7.0: | EC000005 |
| ETIM 6.0: | EC000005 |
| eCl@ss 8.0/8.1: | 36659290 |
| eCl@ss 6.0/6.1: | 36659290 |
| Product description: | Wire end ferrules 1.5 mm ² x 10 mm AWG 16 multinorm, packs of 4,000 pc(s)., colour: black, delivery form: on belt (in accordance with the DIN colour code), 1.5 mm ² |
| Approvals | |
| Approvals: | UR |