

Rittal – The System.

Faster – better – everywhere.

Wire end ferrules on a reel – AS 4051.597

Date : 26.9.2020

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



Wire end ferrules on a reel – AS 4051.597

created: 26.09.2020 build on www.rittal.com/si-sl

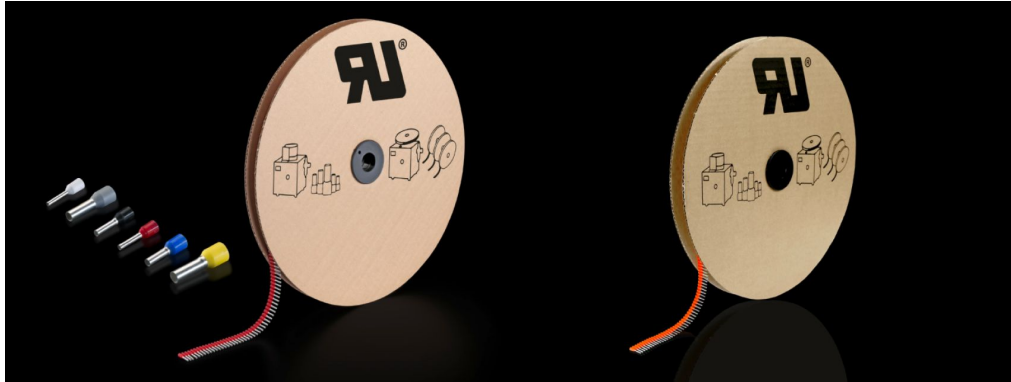

Product description

Description: With plastic collar.

Technical specifications: Heat-resistant to 105 °C

Material: E-Cu, galvanic tin-plated
Plastic collar: Polypropylene

Note: UL-certified in conjunction with the relevant tools, such as crimping machines.

Product features

For cross-section: 0,5 mm²

AWG: 20

Length: 8 mm

Internal diameter: 2,6 mm

Design: for wire processing machines

Colour: Orange

Colour code: Rittal colour code: yes

For: Crimping machine RC
Crimping machine R8
Crimping machine R8 E

Delivery form:	Taped
Packs of:	5000 pc(s).
Copper weight (kg per piece):	0
EAN:	4028177920057
Customs tariff number:	85369010
ETIM 7.0:	EC000005
ETIM 6.0:	EC000005
eCl@ss 8.0/8.1:	36659290
eCl@ss 6.0/6.1:	36659290
Product description:	Wire end ferrules for crimping machines, 0.5 mm ² , AWG 20, 8 mm, orange, on belt, 5000 pc(s).
Approvals	
Approvals:	UR