

Rittal – The System.

Faster – better – everywhere.

Wire end ferrules on a reel – AS 4051.605

Date : 19.9.2020

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



Wire end ferrules on a reel – AS 4051.605

created: 19.09.2020 build on www.rittal.com/si-sl

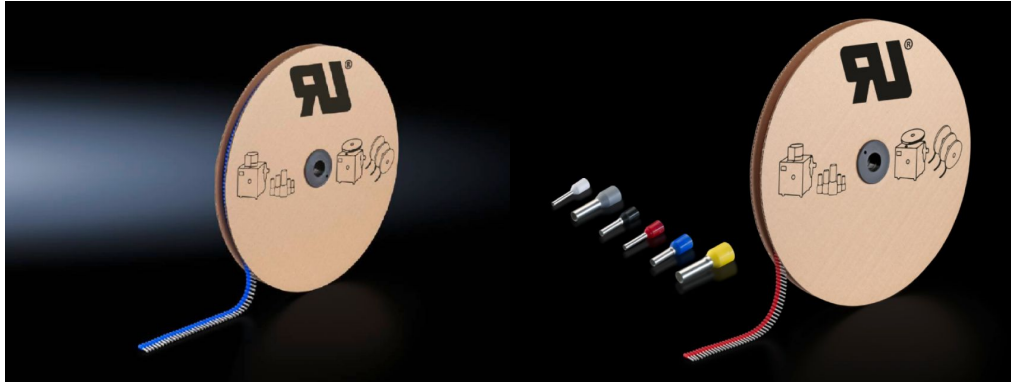

Product description

Description:	With plastic collar.
Technical specifications:	Heat-resistant to 105 °C
Material:	E-Cu, galvanic tin-plated Plastic collar: Polypropylene
Note:	UL-certified in conjunction with the relevant tools, such as crimping machines.

Product features

For cross-section:	2,5 mm ²
AWG:	14
Length:	10 mm
Internal diameter:	4,2 mm
Colour:	Blue
Colour code:	DIN colour code: yes Rittal colour code: yes Multiple colour codes supported: yes
For:	Crimping machine RC
Delivery form:	Taped

Packs of:	3000 pc(s).
Copper weight (kg per piece):	0
EAN:	4028177938649
Customs tariff number:	85369010
ETIM 7.0:	EC000005
ETIM 6.0:	EC000005
eCl@ss 8.0/8.1:	36659290
eCl@ss 6.0/6.1:	36659290
Product description:	Wire end ferrules 2.5 mm ² x 10 mm AWG 14, packs of 3,000 pc(s)., colour: blue, delivery form: on belt (in accordance with the DIN/Rittal colour code)
Approvals	
Approvals:	UR