

Rittal – The System.

Faster – better – everywhere.

► Mounting frame, 482.6 mm (19") for TS, TS IT – DK 5501.242

Date : 11.5.2021

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE



SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



Mounting frame, 482.6 mm (19") for TS, TS IT – DK 5501.242

created: 11.05.2021 build on www.rittal.com/si-sl

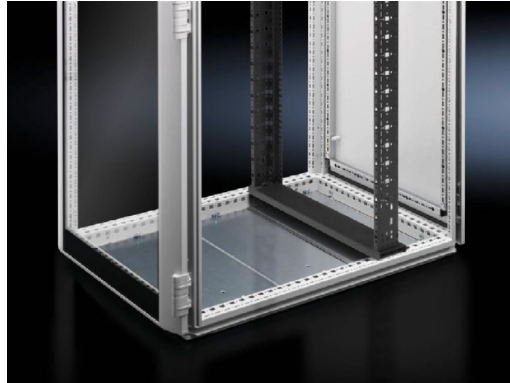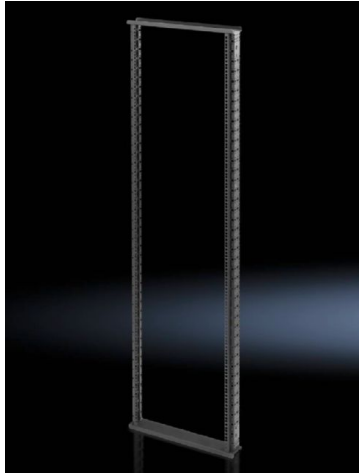

Discontinued article.

This item will be discontinued on: 20.01.2021

Product description

Description: Firmly linked 482.6mm (19") mounting frame for integration of a 482.6 mm (19") mounting level within a TS frame structure. Profiles analogous to TS IT for complete system compatibility, incl. tool-free assembly. Depth-variable mounting between the roof and base frames. Individual height units bi-directionally numbered. Mounting frame at the front, prepared for the integration of cable management and Dynamic Rack Control (RFID), mounting frame at the rear for space-saving integration of the PDU busbar, in the Zero-U space on both sides.

Material: Sheet steel

Surface finish: Primed

Colour: RAL 9005

Supply includes: Assembly parts

Note: The outer mounting level of the enclosure frame is left free for other installed equipment. All-round compartmentalisation with air baffle plates is supported.

Product description

To fit: Enclosure type: TS
Enclosure type: TS IT
Width: 600 mm
Height: 1800 mm

Mounting position:	front
Units:	38 U
Load capacity:	Up to 15,000 N static load, with even load distribution on two 482.6 mm (19") mounting frames, fully configured.
Packs of:	1 pc(s).
Weight/pack:	13 kg
Copper weight (kg per piece):	0
EAN:	4028177716537
Customs tariff number:	73269098
ETIM 7.0:	EC002620
ETIM 6.0:	EC002620
eCl@ss 8.0/8.1:	27189261
eCl@ss 6.0/6.1:	27180907
Product description:	DK Mounting frame, 482.6 mm (19"), For WxH: 600x1800 mm, At the front, RAL 9005
Approvals	
Certificates:	NA