

Rittal – The System.

Faster – better – everywhere.

► Skriňa na stenu AE s 19" profilovými lišťami, hĺbková variabilita – DK 7643.000

Date : 29.9.2020

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



Skriňa na stenu AE s 19" profilovými lištami, hĺbková variabilita – DK 7643.000

created: 29.09.2020 build on www.rittal.com/sk-sk

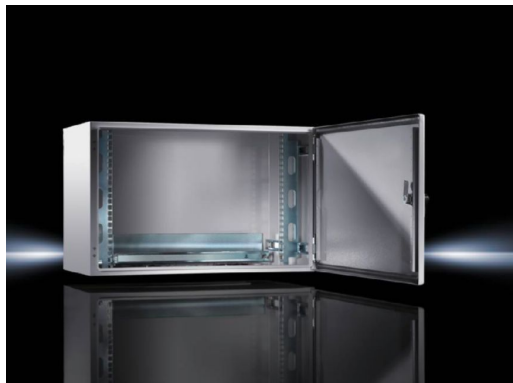

Discontinued article.

Product description

Description:	Wall-mounted enclosure for small networks with a high protection category.
Material:	Enclosure: Sheet steel
Surface finish:	Enclosure: Powder-coated Mounting angles: Zinc-plated
Colour:	RAL 7035
Protection category IP to IEC 60 529:	Up to IP 66 (depending on the selected gland pate)
Supply includes:	Enclosure with hinged door Door hinged on the right, may be swapped to the left Cam lock with 3 mm double-bit insert Gland plate with brush strip for cable entry in the enclosure base Mounting angles, 482.6 mm (19"), fully depth adjustable C rail, for cable clamping on the rear panel Metal bracket for optional accommodation of an earth rail or 482.6 mm (19") socket strip
Basic material:	oceľový plech

Product features

Dimensions:	Width: 600 mm Height: 600 mm Depth: 350 mm
--------------------	--

Installation height for components:	13 U
Installation depth:	310 mm
Door hinge:	right, may be swapped to the left
Number of cam locks:	2
Gland plate, size:	5
Gland plate, qty.:	1
Packs of:	1 pc(s).
Weight/pack:	24,63 kg
EAN:	4028177147034
Customs tariff number:	94032080
ETIM 7.0:	EC002500
ETIM 6.0:	EC002500
eCl@ss 8.0/8.1:	27180208
eCl@ss 6.0/6.1:	27180208
Product description:	DK Wall-mounted enclosures AE, WHD:600x600x350 mm, 13 U, AE 1360

Approvals

Approvals:	Lloyds Register of Shipping NA VDE
-------------------	--